




ENGLISH

Datasheet

AC Axial Fan, 254 Dia. x 88.9mm, 930m³/h, 35W, 115 V ac (OA254 Series)

RS Stock 619-6927

Dimensions: (mm)

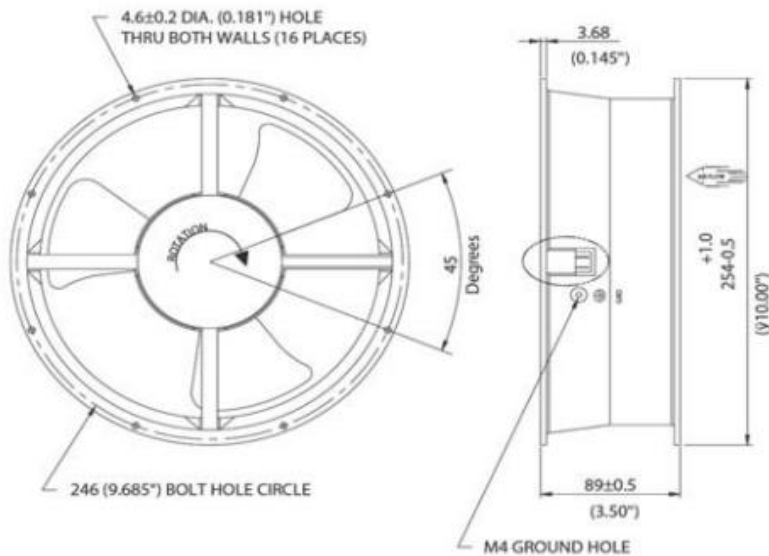



Specifications

- Frame: Die cast Aluminium , Black
- Impeller: PBT , UL94V-0 Thermoplastic

- Motor: High Performance Capacitor Drive, Thermally Protected
- DIELECTRIC STRENGTH :1 minute@1500 VAC, 50/60 Hz
- LIFE EXPECTANCY (L10) :Ball Bearing 60,000 Hours
- Operating Temperature :-20C ~ +80C
- Safety Approvals: UL/CUL, TUV, CE

RS Part No.	Orion Part No.	Speed	Airflow	Noise	Volts	Voltage	Current	Connection Type
6196927		1650	547	55	115	80~130	35	Wire
6196949		1650	547	55	230	160~260	35	Wire