


Compartment door 3VA13 (400 A), 3VA14 (630 A), 3VA23 (400 A), 3VA24 (630 A), fixed-mounted, plug-in design, RCD: without, H: 250 mm W: 600 mm

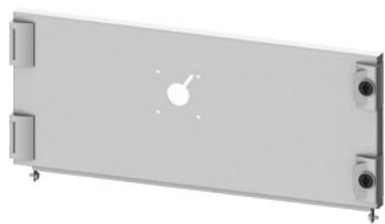

Model	
product brand name	SIVACON S4
product designation	Modular door
design of the product	3VA23 (400 A), 3VA24 (630 A)
design of the surface	Powder-coated
design of the product EMC version	No
Protection class	
protection class IP	IP40
operating resource protection class	1
Appearance	
RAL color number	7035
color	light grey
Product details	
product component	
• ventilation	No
• viewing door	No
• door for disconnecter lock	No
accessories included	no
Mechanical Design	
height	250 mm
width	600 mm
depth	25 mm
opening direction of the door	left / right
mounting position	horizontal
net weight	4 kg
material	sheet-steel
Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Miscellaneous](#)

other	Environment
Confirmation	Environmental Con- firmations
	Environmental Con- firmations

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2025-6BA24>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2025-6BA24>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2025-6BA24

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

last modified:

5/24/2025 

