


Product data sheet

177 W-7/169

EAN-No. 4000896157310



169-pieces · 7 Drawers total

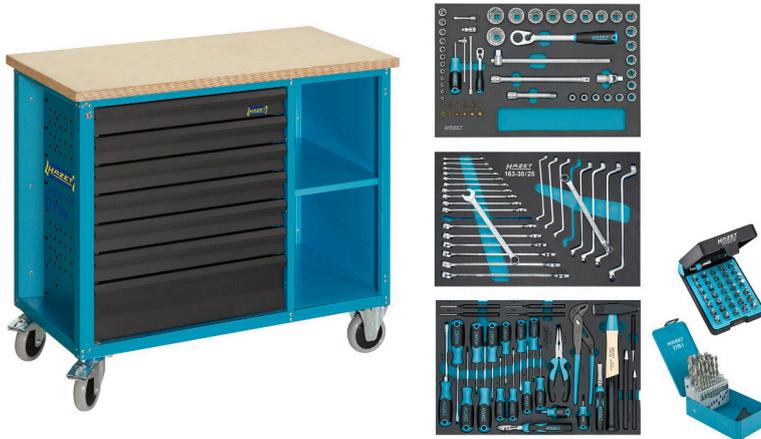

- 6 x flat drawers and 1 x high drawer as well as 2 storage shelves in the storage compartment
- Complete with 169-piece tool assortment in Safety-Insert-System soft foam insert
- Large ball-bearing wheels (Ø 125 mm), easy manoeuvrability, even with high dynamic load
- 2 swivel castors with dual brake:
 - Braked castors prevent rolling away
 - Braked swivel bearings prevent the swivel castors from turning, e.g. on inclined surfaces
- Protective ring prevents dirt and threads from getting in
- Grey non-marking elastic tyres enable smooth movement
- Two-stage locking concept:
 - Central locking, lockable with cylinder lock and 2 keys
 - Individual drawer locking prevents unwanted drawer opening
 - 100% sliding-out with ball-bearing guiding rails
- Boards in the storage compartment:
 - Loading capacity top: 15 kg / bottom 35 kg
 - Storage shelves adjustable
- Optional: 177W-21: Door for right storage compartment, lockable, including 2 keys
- Total loading capacity (dynamic): 500 kg
- Loading capacity (static): 750 kg
- Worktop: Wood multiplex birch, replaceable
- Loading capacity of high drawer: 20 kg
- Colour: HAZET blue
- Tool trolley Made in Germany
- Dimensions: 1040 mm x 520 mm x 934 mm
- Net weight: 88.1 kg
- Drawers, flat: 6 x 79 x 527 x 348 mm
- Drawers, high: 1 x 164 x 527 x 348 mm
- (Drawer) size for plastic drawer insert: 3/3
- Number of separation sheets: 7
- Worktop: Wood multiplex birch, replaceable
- Worktop height: 934 mm
- Number of fixed castors: 2 (Ø 125 mm)
- Number of swivel castors: 2 (Ø 125 mm)
- The drawers are equipped with one separation sheet each as standard

