


5380636

Pipe Cleaning Brush f/handle, 145 mm, Hard, Yellow

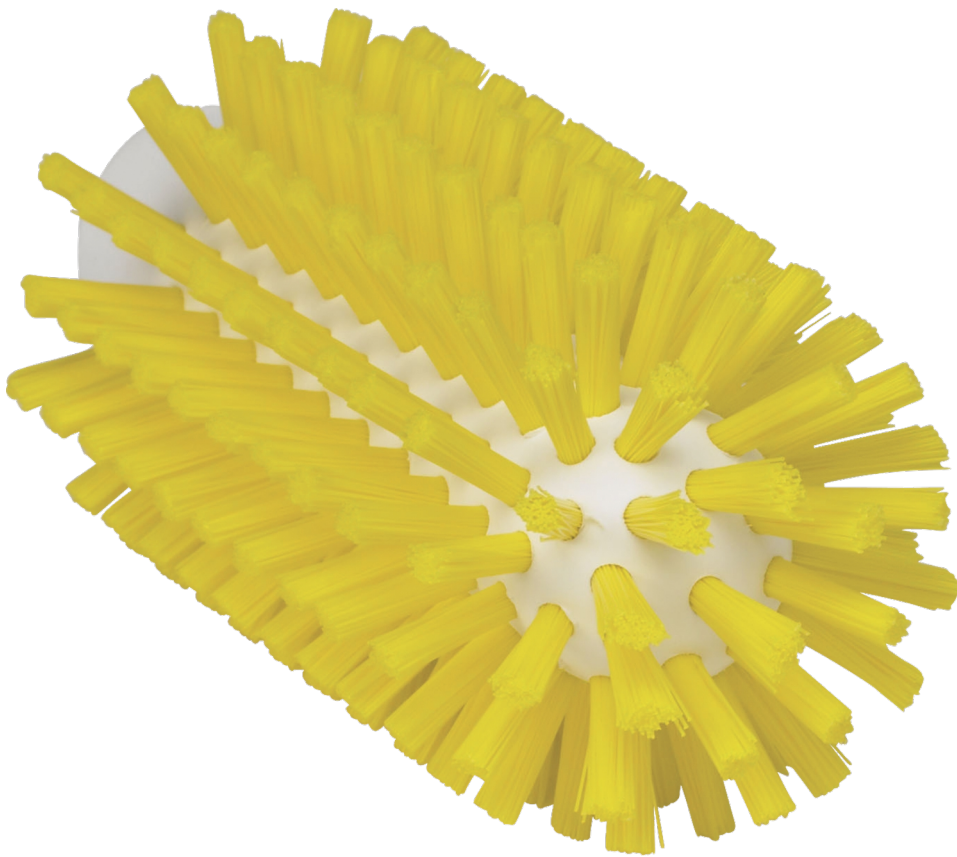

Fits all Vikan-handles. Tube cleaner is effective for cleaning of various kinds of tubes. Suitable for cleaning of e.g. sorting machines in the fishing industry or meat mincers in a butchery shop.

Technical Data

Item Number	5380636
Visible bristle length	11 mm
Material	Polypropylene Polyester Stainless Steel
Suitable for Food Contact (EU 1935/2004), DoC ¹	Yes
Produced according to EU Regulation 2023/2006/EC of Good Manufacturing Practice	Yes
FDA compliant raw material (CFR 21)	Yes
Meets the REACH Regulation (EC) No. 1907/2006	Yes
Use of Phthalates (e.g. Bisphenol A)	No
Is Halal compliant	Yes
Box Quantity	15 Pcs.
Quantity per Pallet (80 x 120 x 200 cm)	1560 Pcs
Quantity Per Layer (Pallet)	120 Pcs.
Box Length	380 mm
Box Width	290 mm
Box Height	140 mm
Product Diameter	63 mm
Length	145 mm
Width	65 mm
Gross Weight	0,138 kg
Net Weight	0,119 kg
Cubik metre	0,0006 M3
Recommended sterilisation temperature (Autoclave)	121 °C
Max. cleaning temperature (Dishwasher)	93 °C
Max usage temperature (food contact)	80 °C
Max usage temperature (non food contact)	100 °C
Min. usage temperature	-20 °C
Min. pH-value in usage concentration	2 pH
Max. pH-value in Usage Concentration	10,5 pH
Gtin-13 Number	5705025380667
GTIN-14 Number (Box quantity)	15705025380664
Commodity Code	96039099
Country of origin	Denmark

New equipment should be cleaned, disinfected, sterilised and any labels removed, as appropriate to its intended use, e.g. high risk vs. low risk food production areas, general hospital areas vs. intensive care units, before use.