

ERG'O® PRO



REF.
NLRG

Adjustable work positioning lanyard and temporary anchor device




neofeu.com

REGULATION


2016 / 425

CERTIFICATION

EN 358 : 2018
EN 795 : 2012 - B

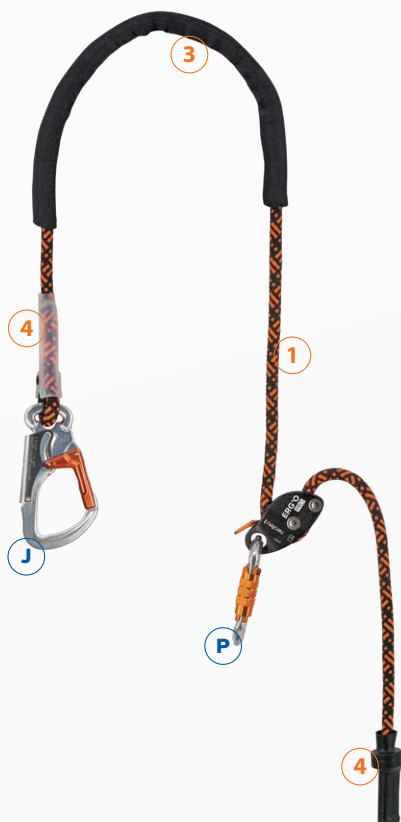


TECHNOLOGIES

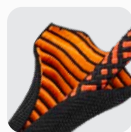

FLEX WRAP
Self-wrapping
protection
sheath



EN 358 & EN 795-B
Certified for work
positioning, restraint
and anchorage use

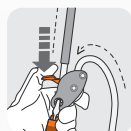

PRESS & ADJUST
Quick
adjustment
lever



LIGHTWEIGHT
Only 120g for
the aluminium
adjuster

TECHNICAL SPECIFICATIONS

- Maxi user weight 140kg
- 1 • Ø11mm high-tenacity polyamide sheathed braided rope
- Dual function: work positioning and restraint lanyard, usable as a temporary anchor device
- 2 • Aluminium alloy adjuster
- 3 • Removable self-wrapping woven protection sheath
- 4 • Sewn terminations with plastic thimbles and protective sleeve
- Weight : 630g (NLRG20PJ; 2m lanyard with connectors)

Available in different lengths, from 1 to 10m.

DESCRIPTION

ERG'O® PRO is an adjustable work positioning lanyard designed to provide **precise and comfortable positioning** during work at height.


Certified for **work positioning** and as a **temporary anchor device**, it features a **progressive adjustment system** allowing smooth and accurate length adjustment, even under load, to achieve the ideal working position according to the task configuration.

It can be used on the harness, on lateral attachment points for work positioning or on the ventral attachment point to adjust the distance from the anchor, **ensuring full control** and balanced weight distribution.

Integrating an **Ø11 mm rope**, it includes **self-wrapping FLEX WRAP sheath**, which provides effective protection against abrasion and sliding over structures.

Equipped with aluminium connectors depending on the version, **ERG'O® PRO** is available in various lengths from 1 to 10m.

EN 795-B

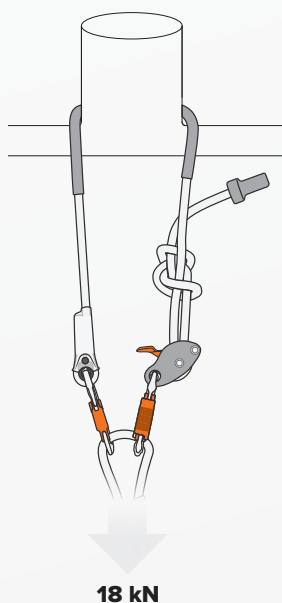

18 kN



ERG'O PRO lanyard is available as standard with the following aluminium connectors :

P

NM17ALU



J

NM26LFA



A

NM16NS



M

NM20ALUB



C

NM28N.O



Other removable or non removable connectors are available on request. *See our available connectors.*