



Brand of NTN corporation


Technical data

BBES16AUU

Standard ball bushings closed



VISUAL (S)

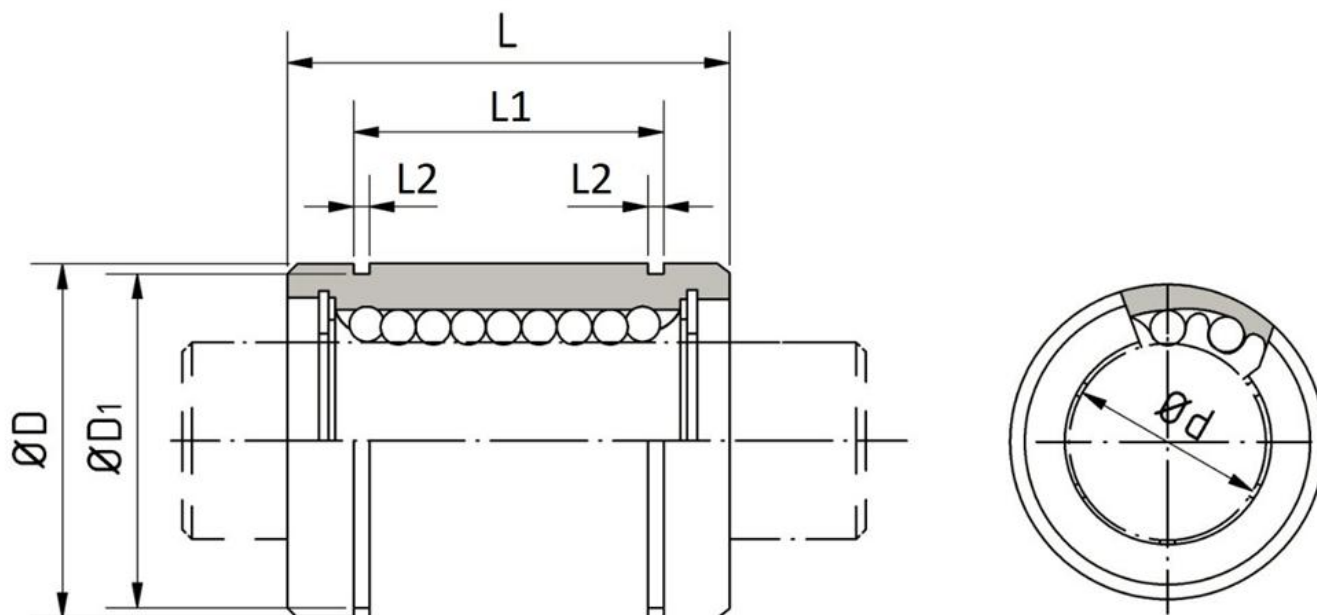

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	X105CrMo17
Material Cage	X5CrNi18-10
Initial greasing	Non/No
d - Internal diameter	16 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter tolerance	0,009/-0,001
D - External diameter	26 mm
D - External diameter tolerance	0/-0,009
L - Length	36 mm
L - Length tolerance	0/-0,2
L1	24,9 mm
L1 tolerance	0/-0,2
D1 - Diameter	24,9 mm
L2	1,3 mm
Number of ball rows	4
Mass	0,06 kg

PRODUCT PERFORMANCE

Cmin	0,526 kN
Cmax	0,744 kN
C0min	0,892 kN
C0max	1,261 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	140 °C

ESHOPDONOTDISPLAY

Reference	BBS16AUU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

