

# UNIQUE TUBE CUTTER



The wide range of automatic Pipe cutters of EGA Master is designed for the easy and quick cut of different materials and sizes tubes, following the needs of the user. Its precision machining provides the quickest and smoothest action.

*Able to cut copper, inox and plastic pipes with the proper cutting wheels.*



**1. Designed for the cutting and reaming of copper pipes, it is extremely robust, compact and easy to use.**




**2. Laser marked graduated scale to facilitate working action.**






**3. Extra cutting wheel at the knob.**


**4. Extractable reamer can work assembled in the tubing cutter or independently.**

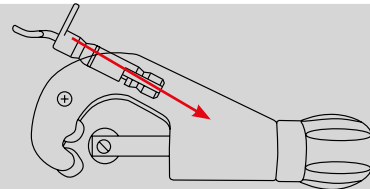



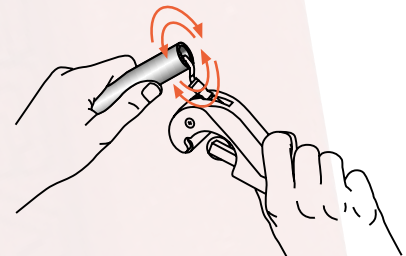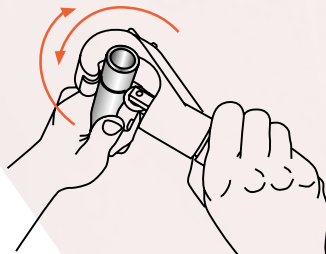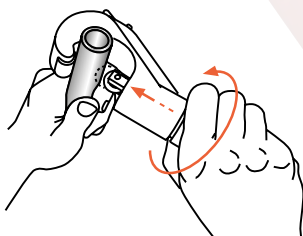



**5. Gold Medal, International Inventors Competition, Paris 2004.**










**MINI TUBE CUTTER**




| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63176      | CU          | 3-16  | 90   | 20  | 1   | 63088   | 20  |
| 63106      |             | 3-22  | 120  |   |   |   |   |







**MINI 30 TUBE CUTTER**




| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63168      | CU          | 3-30  | 210  | 10  | 1   | 63086   | 20  |







**CLASSIC 32 TUBE CUTTER**




| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63170      | CU          | 3-32  | 300  | 1   | 1   | 63110   | 20  |







**TELESCOPIC 32 TUBE CUTTER**




| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63105      | CU          | 6-32  | 290  | 1   | 1   | 63110   | 20  |







**UNIQUE TUBE CUTTER**




| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63119      | CU          | 6-42  | 550  | 8   | 1   | 63111   | 10  |
| 63187      |             | 6-45  | 600  | 1   |   |   |   |







**AUTOMATIC 50 TUBE CUTTER**



| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63363      | CU          | 6-50  | 450  | 1   | 1   | 63720   | 10  |

**AUTOMATIC 67 TUBE CUTTER**



| <b>COD</b> | <b>MAT.</b> |  <b>O.D.</b> |  <b>gr.</b> |  |  |  |  |
|------------|-------------|---|--|---|---|---|---|
| 63107      | CU          | 6-67  | 750  | 1   | 1   | 63111   | 10  |

**AUTOMATIC 127 TUBE CUTTER**



| <b>COD</b> | <b>MAT.</b> | O.D.   | gr.  |   |   |       |    |
|------------|-------------|--------|------|---|---|-------|----|
| 63174      | CU          | 50-127 | 1950 | 1 | 1 | 64106 | 10 |

**KIT**



| <b>COD</b> |                       |
|------------|-----------------------|
| 69465      | 63106 - 63170 - 63119 |

**ROLLCUT**



| <b>COD</b> | <b>MAT.</b> | O.D. | gr. |   |   |       |    |
|------------|-------------|------|-----|---|---|-------|----|
| 63210      | CU          | 12   | 230 | 6 | 1 | 63243 | 10 |
| 63211      |             | 15   | 220 |   |   | 63244 |    |
| 63212      |             | 18   | 250 |   |   | 63245 |    |
| 63213      |             | 22   | 240 |   |   | 63246 |    |

# TECHNICAL SPECIFICATIONS

|                 |  |  |
|-----------------|--|--|
| <b>MATERIAL</b> | <b>Body, carriage and knob</b>                         | 63176-63106-63168-63170-63105-63077-63119-63187:<br>Zinc alloy |
|                 |  | 63363-63107-63174: Aluminum alloy                              |
|                 | <b>Cutting wheel</b>                                   | Special steel  |
|                 | <b>Reamer</b>  | Special steel  |
| <b>HARDNESS</b> | <b>Cutting wheel and reamer</b>                        | 55-60 Hrc  |
| <b>FINISH</b>   | <b>Body</b>  | Painted in epoxi powder red color<br>Ral-2002 semi-texturized  |
|                 | <b>Knob</b>  | Painted in epoxi powder black color semi-texturized            |
|                 | <b>Screw, cutting Wheel, axle of the Cutting wheel</b> | Black finish   |
|                 | <b>Rollers</b>   | Black finish   |