


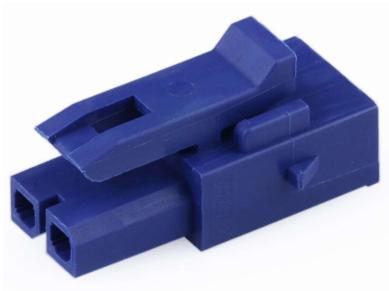

**Part Number :** [2157591034](#)  
**Product Description :** Micro-Fit+ Versa Color Receptacle Housing, Single Row, 4 Circuits, UL 94V-0, Glow-Wire Capable, Blue  
**Series Number :** 215759  
**Status :** Active  
**Product Category :** Connector Housings



## Documents & Resources

### Drawings

- [2157591034\\_sd.pdf](#)
- [2157590003-PK-000.pdf](#)

### 3D Models and Design Files


- [2157591034\\_stp.zip](#)

### Specifications

- [2064600001-AS-000.pdf](#)
- [2159530000-PS-000.pdf](#)
- [2064600001-TS-000.pdf](#)
- [2157590005-TS-000.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

## Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	Connector Housings
Series	215759
Description	Micro-Fit+ Versa Color Receptacle Housing, Single Row, 4 Circuits, UL 94V-0, Glow-Wire Capable, Blue
Application	Power, Wire-to-Board, Wire-to-Wire
Product Name	Micro-Fit+ Versa Color
UPC	196823364211

#### Agency

CSA	LR19980
-----	---------

#### Physical

Circuits (maximum)	4
Color - Resin	Blue
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.563/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No

Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +125°C

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Micro-Fit+ Right-Angle, Single Row, Through Hole Headers	<u>215760</u>
Micro-Fit+ Vertical, Single Row, Through Hole Headers	<u>216571</u>
Micro-Fit+ Single Row Surface Mount Headers	<u>218989</u>

### Use with Part(s)

Description	Part Number
Micro-Fit+ Female Crimp Terminals	<u>206460</u>
Micro-Fit+ Terminal Position Assurance (TPA) Retainers	<u>206462</u>