



Electrical Accessories for C60 Circuit Breakers and Supplementary Protectors

Possible Combinations

Mounted to the left of the circuit breaker with a maximum width of 54 mm.

 
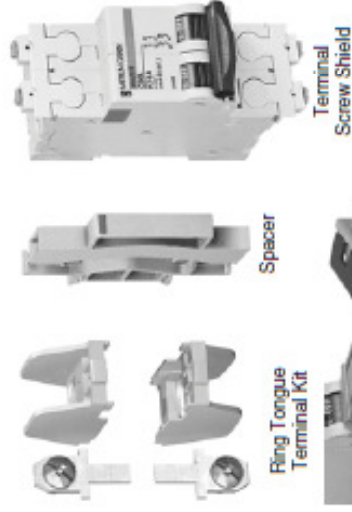


Table 7.33: Multi 9 C60 Electrical Accessories

Descriptions	Control Voltage			Width in 9 mm modules	C60 UL/IEC	
	Vac	Vdc	Cat. No.			
OF Auxiliary Switch (1a1b)	12-277	12-125	1	1	MC26825	
SD Alarm Switch (1a1b)	12-277	12-125	1	1	MC26828	
MX Shunt Trip + OF Auxiliary Switch (1a1b)	24	24	2	2	27118	
	48	48	2	2	27110	
	110-240-277	125	2	2	27109	
MN Undervoltage Release	24	24	2	2	27108	
	48	48	2	2	27106	
	120	—	2	2	27107	
	240	—	2	2	27105	
Multi-9 GFP UL 1053 Listed Ground Fault Protectors	120 to 480V/277 Vac; 30, 100, and 300 mA; 2P and 4P.					
See page 7-18, Handout, 0860H00602 or Catalog 0860CT0201						

Table 7.34: Multi 9 C60 Mechanical Accessories

Descriptions		C60	
		Cat. No.	
Hing tongue terminal kit for UL1077 C60N	For one pole	1/000	
Spacer for DIN rail, Not UL Recognized	9 mm wide	MC27082	
Padlock Attachment (1 per for 1P, 2P, 3P or 4P)	2 per pack	MC26870	
Heavy-duty Padlock Attachment for C60N, Locks OFF only	2 per pack	MG26845	
Padlocking Device Left Side Mount, Locks OFF only▲	1 per pack	MGN26380	
Padlocking Device Right Side Mount, Locks OFF only■		MGN26381	
Front Mounting Kit		MC26883	
	1P	MC26884	
	2P	MC26885	
	3P	MC26886	
	4P	MC26889	
Label holders for 2, 3 or 4P C60 (Not UL Recognized)	Bag of 10	MC27150	
Terminal Screw Shield (Not UL Recognized)	Bag of two 4P shields	MC26881	
Terminal cover (Not UL Recognized)	1P	MC26875	
	2P	MC26876	
	3P	MC26875+MC26876	
	4P	MC26878	
Comb Bus Bar Kit for UL1077 C60, 12 poles, Fixed Length	10	MG10285	
	20	MG10286	
	30	MG10287	
tooth Caps for UL Comb Bus Bar, Bag of 20		60488	
Rotary Handle for C60 (Non UL Recognized)			
Operating Subassembly			
Door Interlock Handle			
Fixed Handle (Front or Lateral)			
Multi-pole Front Mounting Kit			
Rail Support (20 of 9 mm modules)			
Hinged Transparent Cover			

- ▲ Left-side mounted padlocking device cannot be used in conjunction with accessories SD, OF, MX or MN. Use right-side mounted padlocking device when accessories are required.
- Right-side mounted padlocking device cannot be used in conjunction with VIGI module. Use left-side mounted padlocking device when VIGI Module is required..

Multi 9 SPD (Surge Protective Device) see Page 6-6