

# RewoCold® 644




## APPLICATION

- › metal and plastics processing
- › metalworking and mechanical engineering
- › automotive and supply industry
- › cleaning and maintenance
- › metal processing
- › assembly and transportation works
- › working with oily and wet parts

## QUALITIES AND ADVANTAGES

- › breathable artificial leather
- › no material hardening
- › absorbent surface profile for a sure grip
- › short-term cold protection down to -20°C
- › very good fit
- › good dexterity




|                      |  |
|----------------------|--|
| Article no.          | 644  |
| Name                 | RewoCold® 644  |
| Material             | artificial leather palm, felt  |
| Description          | artificial leather, moisture barrier, insulation inlay for cold, cuff  |
| Length (mm)          | 250 - 310  |
| Total thickness (mm) | 1,8 ± 0,15   |
| Colour               | grey/black   |
| Size                 | 7, 8, 9, 10, 11, 12  |
| Classification       | category II<br>EN388:2016<br> to -20°C<br>2111X |



## FEATURES

- › free from Chromate VI
- › terry cloth material for sweat absorption
- › cuff for quick donning and doffing
- › with one-sided moisture barrier
- › with warming fleece inlay

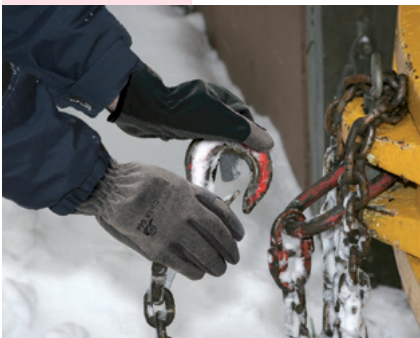

[www.kcl.de](http://www.kcl.de)  
[sales@kcl.de](mailto:sales@kcl.de)



by Honeywell

## KCL GmbH

Industriepark Rhoen  
Am Kreuzacker 9  
36124 Eichenzell  
Germany  
Phone +49 6659 87-300  
Fax +49 6659 87-318