


8048123 DFPD-120-RP-90-RD-F0507 Semi-rotary drive - Series: All

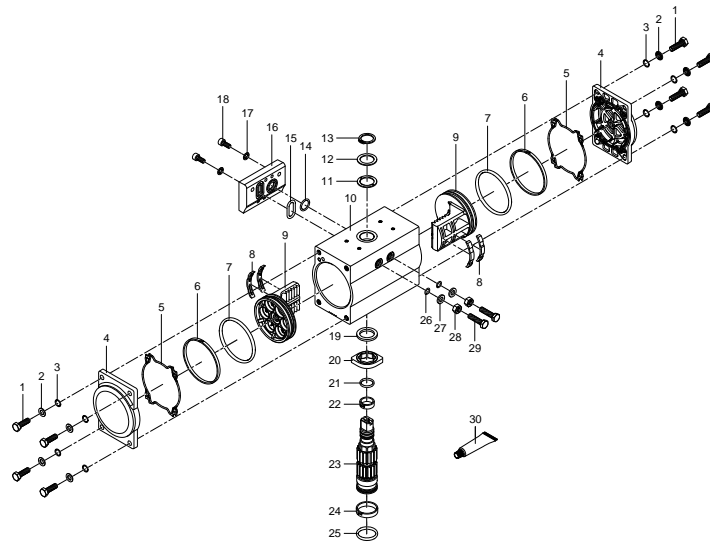

## 8048123 DFPD-120-RP-90-RD-F0507 Semi-rotary drive - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	8190152	DFPD-120-.. REV1 Set of wearing parts	Spare parts: 3, 5, 6, 7, 8, 11, 13, 14, 15, 17, 19, 21, 22, 24, 25, 26, 27, 28, 29 <a href="#">▶ Replacing the wearing parts</a> Attention, please order position 30 as well	1	PC
1		ISO 4017-M8X25-A2-70 Hexagon head screw	Not available Tightening torque 23.5 Nm / 17.3 lbf ft	8	PC
2		8,3X15X1,5-1.4301 Ring	Not available	8	PC
3		DIN 6797-J-8,4-A2-70 Toothed disc	Not available separately, see position A	8	PC
4		DFPD-120-D End cap	Not available	2	PC
5		DFPD-120 Moulded seal	Not available separately, see position A	2	PC
6		DFPD-120-../T6 Slip ring	Not available separately, see position A <a href="#">▶ Repair note: Slip_ring</a>	2	PC
7		80X4,5-N-NBR70 O-ring	Not available separately, see position A	2	PC
8		DFPD-120-../T6 Slide element	Not available separately, see position A	4	PC
9		DFPD-120-90 Piston	Not available Lubricate with SYNTHY POLYMER 402/2 during assembly	1	PC
10		DFPD-120-90-F0507-AN Housing	Not available Lubricate with SYNTHY POLYMER 402/2 during assembly	1	PC
11		DFPD-120-../T6 Slip ring	Not available separately, see position A	1	PC
12		DIN 988-25X35X1-A2 Shim	Not available	1	PC
13		DIN 471-25X1,2-A2 Retaining ring	Not available separately, see position A	1	PC
14		B-16X2-N-NBR70 O-ring ISO3601	Not available separately, see position A	1	PC
15		B-21X2-N-NBR70 O-ring ISO3601	Not available separately, see position A	1	PC
16		DFPD-120/160-AN Sub-base	Not available	1	PC
17		J-5,1-A2-70 Toothed disc	Not available separately, see position A	2	PC
18		ISO 4762-M5X16-A2-70 Socket head screw	Not available Tightening torque 7 Nm / 5.2 lbf ft	2	PC
19		DFPD-120-../T6 Slip ring	Not available separately, see position A	1	PC
20		DFPD-120-90 Cam	Not available	1	PC
21		B-20,24X2,62-N-NBR70 O-ring ISO3601	Not available separately, see position A	1	PC
22		DFPD-120-../T6 Slip ring	Not available separately, see position A <a href="#">▶ Repair note: Slip_ring</a>	1	PC
23		DFPD-120-KT17 Shaft	Not available Lubricate with SYNTHY POLYMER 402/2 during assembly	1	PC
24		DFPD-120-../T6 Slip ring	Not available separately, see position A <a href="#">▶ Repair note: Slip_ring</a>	1	PC
25		B-36,14X2,62-N-NBR70 O-ring ISO3601	Not available separately, see position A	1	PC

Pos.	Part no.	Type	Note	Qty.	Unit
26		B-7,59X2,62-N-NBR70 O-ring ISO3601	Not available separately, see position A	2	PC
27		8,2X16X1,5-1.4301 Ring	Not available separately, see position A	2	PC
28		DIN 934-M8-A2-70 Hex nut	Not available separately, see position A Tightening torque 23.5 Nm / 17.3 lbf ft	2	PC
29		DFPD-120 adjusting screw	Not available separately, see position A	2	PC
30	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease	Not included in wearing-parts kit	1	PC