



fitted with

- work equipment**
- connected load**
- power consumption**
- light colour**
- color rendering index (CRI)**
- glare-free**
- system of protection**
- class of protection**
- usage**
- luminaire body**

- lamp cover**
- tubular sections**

- balance of articulation joints**
- weight (net)**
- mains lead**

fastening

LED


- Energy efficiency category A+
- electronic transformer
- 100-240 V; 50/60 Hz
- approx. 34 W
- neutral white, approx. 4000 K
- > 80
- conical prismatic screen
- IP 20
- II
- multi-function switch
- sectional aluminium, anodised, aluminium coloured
- anodised
- acrylic clear
- tubular aluminium section, anodized, aluminium coloured
- anodised
- spring
- approx. 2.3 kg
- approx. 3,7 m; mains plug
- CEE 7/XVI
- screw-down flange, table clamp (accessory), wall bracket (accessory)



CEE 7/XVI

illuminance

distance: 50 cm
Em: 1641 lx
Emax: 4046 lx
Emin: 329 lx

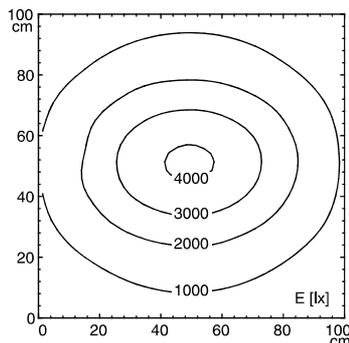

luminous intensity

