

Previously known as: Black Heavyweight G17K

## Thicker natural rubber, latex glove with extra protection in heavy duty applications

- High resistance to water based chemicals.
- Good resistance to abrasion.
- Resistant and flexible, suitable for many industrial applications.
- Flock lined 100% cotton.
- AQL 0.65



### Industries

- Chemical
- Metal fabrication
- Machinery and Equipment
- Automotive Aftermarket

### Applications

- Loading and unloading of process equipment
- Loading raw material
- Transferring liquids and solids between vessels and tanks and process equipment
- Assembly and disassembly of equipment
- Production line support & maintenance

# AlphaTec®

ADVANCED CHEMICAL PROTECTION

## 87-118

Extra-heavyweight natural rubber glove with flocked lining

Previously known as: Black Heavyweight G17K

### Key Features


- Beaded cuff for easy donning /doffing
- Flexible heavy duty with 0.8 mm / 31 mils glove thickness
- Diamond grip pattern
- Cuff improve tear resistance and helps prevent droplets travelling beyond the glove.
- 100% cotton flock lining

### Vulcanization Chemical Accelerators

- Natural rubber proteins
- Parabens
- Zinc Dibutyldithiocarbamate
- Zinc Diethyldithiocarbamate
- Zinc 2-mercaptobenzothiazole

Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.

### Performance Standards

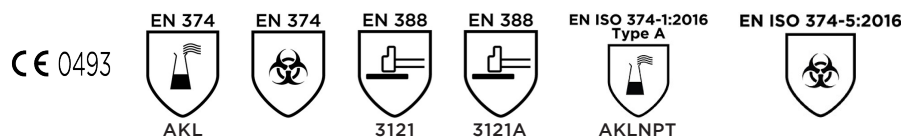

### Specifications

BRAND   STYLE	DESCRIPTION	SIZE	LENGTH	COLOR	PACKAGE
AlphaTec® 87-118	Cotton Flocking, Natural Latex Rubber,	6.5, 7.5, 8.5, 9.5, 10.5	320 mm/ 12 inches	Black	<ul style="list-style-type: none"><li>• 1 pair per inner bag, 12 inner bags per master bag, 12 master bags per carton ( FOR EMEA / APAC )</li><li>• 12 pairs per bag, 12 bags per carton ( FOR NA/LAC )</li></ul>

#### Europe, Middle East & Africa Region

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
T: +32 (0) 2 528 74 00  
F: +32 (0) 2 528 74 01

#### North America Region

Ansell Healthcare Products LLC  
111 Wood Avenue South,  
Suite 210  
Iselin, NJ 08830, USA  
T: +1 800 800 0444  
F: +1 800 800 0445

#### Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.  
Blvd. Bernardo Quintana No. 7001-C,  
Q7001 Torre II,  
Suites 1304, 1305 y 1306,  
Col. Centro Sur, c.p. 76079  
Queretaro, Qro. Mexico  
T: +52 442 248 1544 / 248 3133

#### Canada

Ansell Canada Inc.  
105, rue Lauder  
Cowansville (Québec)  
J2K 2K8, Canada  
T: 1 800 363-8340  
F: 1 888 267-3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:  
[www.ansell.com/patentmarking](http://www.ansell.com/patentmarking) © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.