

No. 3100VA-1 Double Action VA cable stripper Patent Pending




Eco-friendly

- Even PE sheath cables can be stripped beautifully.
- Smallest grip span in the industry. Improves work efficiency.
- Ergonomic handle fits in the palm and reduces fatigue.

Model No.	Overall length mm	Weight g	Wire size	Outer Ctn.
3100VA-1	185	370	PVC cables (VVF/ VA cables) PE cables (EM-EEF/ Eco cables) φ 1.6mm duplex/ φ 2.0mm duplex φ 1.6mm triplex/ φ 2.0mm triplex	5

No. 3000 Wire Stripper

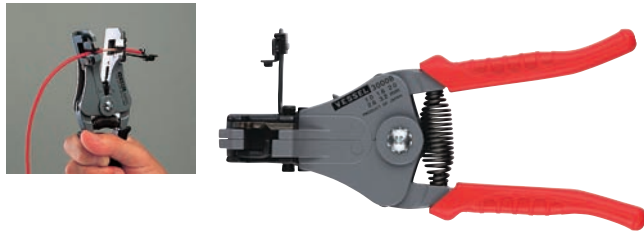

Eco-friendly

- Nimble and cleanly strips off sheathing in a single operation.
- Resin grip comfortably fits in the palm and reduces fatigue.
- Available in 6 types according to target wire.
- Can be used with wiring for TV, radio, home appliances, electrical work, automotive circuits, telephones, etc.

Model No.	Overall length mm	Weight g	Wire diameter and nominal sectional area	Handle color	Outer Ctn.
3000A	170	350	0.5/ 1.2/ 1.6/ 2.0 mm (For solid wire)	Green	20
3000B	170	350	1.0/ 1.6/ 2.0/ 2.6/ 3.2 mm (For solid wire)	Red	20
3000C	170	350	0.9/ 1.25/ 2.0/ 3.5/ 5.5 mm ² (For strand wire)	Black	20
3000D	170	350	0.75 mm ² X2-wire/ 1.25 mm ² X2-wire (For flat vinyl wire)	Orange	20
3000G	170	350	3.8 mm/ 5.6 mm/ core wire (For 3C2V, 5C2V coaxial cable)	Dark blue	20
3000VA	170	350	1.6 mmX2-wire/ 2.0 mmX2-wire (For VA, IV wire)	Blue	20

Strip gauge provided only on 3000A, B, C and D.

No. WB Wire Stripper Blade for No. 3000



Model No.	Applicable wire stripper
WB-001	3000 A
WB-002	3000 B
WB-003	3000 C
WB-004	3000 D
WB-008	3000 G
WB-007	3000 VA

- Replaceable blade of No. 3000 stripper.

<p>NO.3000 ● For solid wire</p> <p>A VESSEL 0.5 1.2 1.6 2.0</p>	<p>NO.3000 ● For flat vinyl wire</p> <p>D VESSEL</p>
<p>● For strand wire</p> <p>B VESSEL 1.0 1.6 2.0 2.6 3.2</p>	<p>● For 3C2V, 5C2V coaxial cable</p> <p>G VESSEL 3C2V 5C2V Cuts Wire</p>
<p>● For VA, IV wire</p> <p>VA VESSEL 1.6X2 2.0X2</p>	

No. 3500E-1/3500E-2 Wire Stripper



Eco-friendly

- Lightweight (100g), compact handy type.
- Diamond polished blade for precision stripping.
- AWG-mm-mm2 conversion table on grip.


Model No.	Overall length mm	Weight g	Wire diameter and nominal sectional area	Handle color	Inner Ctn.	Outer Ctn.
3500E-1	155	100	AWG 24/22/20/18/16/14/12	Red	5	30
3500E-2	155	100	AWG 30/28/26/24/22/20/18	Yellow	5	30

No. 3700KR Cable Stripper



- Wide stripping range applicable with most cables.
- Simply turn a dial to set strip depth.
- Lightweight, compact and easy to carry.

Overall length mm	Weight g	Strip Capacity	Inner Ctn.	Optional
122	60	Seath O/ D 4.5~26mmφ	1	Blade No.3700KR-1 Blade holder set No.3700KR-2

 

- Strips cable sheathing of 4.5~26 mmφ OD.
- Can smoothly make longitudinal cuts by pressing a button.

WARNING Concerning Wire Strippers

- Do not use on live wires.
- Cut sheathing can fly about, therefore be careful of surrounding area when working.
- Check product capacity and specifications before use. Use products of a suitable size.