
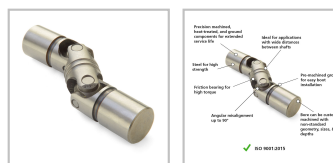


Ruland UD32-XX-XX-F, Machinable Bore Double Universal Joint, Friction Bearing, Steel, 1.995" (50.7mm) OD, 8.688" (220.7mm) Length

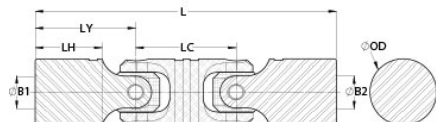

Ruland UD32-XX-XX-F is a double cardan friction bearing universal joint with plain bores that can be machined to a bore size and geometry of the user's choice. It has a 1.995" (50.7mm) OD and 8.688" (220.7mm) length. UD32-XX-XX-F is ideal for applications with wide distances between shafts and can accommodate all forms of misalignment. This plain bearing double universal joint is comprised of pins and blocks that are precision machined, selectively heat treated, and ground for high strength, accuracy, and wear resistance. The combination of these components with precision ground and hardened yoke ears allow for a longer lifespan, increased performance in demanding applications, and greater angular misalignment of up to 90° when compared to commodity style double universal joints. UD32-XX-XX-F is made from high grade alloy steel for durability and high strength. It can be combined with boot UBOOT32/51-NI-KIT to protect the joints from unwanted contaminants such as dust or water and self lubricate reducing maintenance time. This double cardan universal joint is manufactured in the USA by Belden Universal for strict control of processes.

Bore (B1)	No Bore	Small Bore (B2)	No Bore
B1 Max Shaft Penetration	1.700 in (43.2 mm)	B2 Max Shaft Penetration	1.700 in (43.2 mm)
Joint Outer Diameter (OD)	1.995 in (50.7 mm)	Length (L)	8.688 in (220.7 mm)
Center Yoke Length (LC)	3.188 in (81.0 mm)	Yoke Length (LY)	2.750 in (69.9 mm)
Hub Depth (LH)	1.700 in (43.2 mm)	Max Round Bore (Inch)	1.1875 in
Max Round Bore (Metric)	30 mm	Max Hex or Square Bore (Inch)	1.1250 in
Max Hex or Square Bore (Metric)	30 mm	Max Blind Bore (Inch)	1.5000 in
Max Blind Bore (Metric)	38 mm	Max Round Bore w/ Key (Inch)	1-3/16" Bore, 1/4" Keyway
Max Round Bore w/ Key (Metric)	30mm Bore, 8mm Keyway	Peak Torque	19350 in-lb (2186.3 Nm)
Rated Torque	3,870 in-lb (437.3 Nm)	Max Operating Angle	90°
Material Specification	Alloy Steel	Manufacturer	Belden Universal
Country of Origin	USA	Weight (lbs)	6.075000
Recommended Lubricant	LUBRIPLATE No. 1200-2	Matching Boot Cover	UBOOT32/51-NI-KIT
UPC	634529288702	Tariff Code	8483.60.4000

Prop 65  **WARNING** This product can expose you to the chemical Ethylene Thiourea, known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.