

Features

Long Locking Latch


RS PRO IDC Connectors

RS Stock No.: 0360675



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

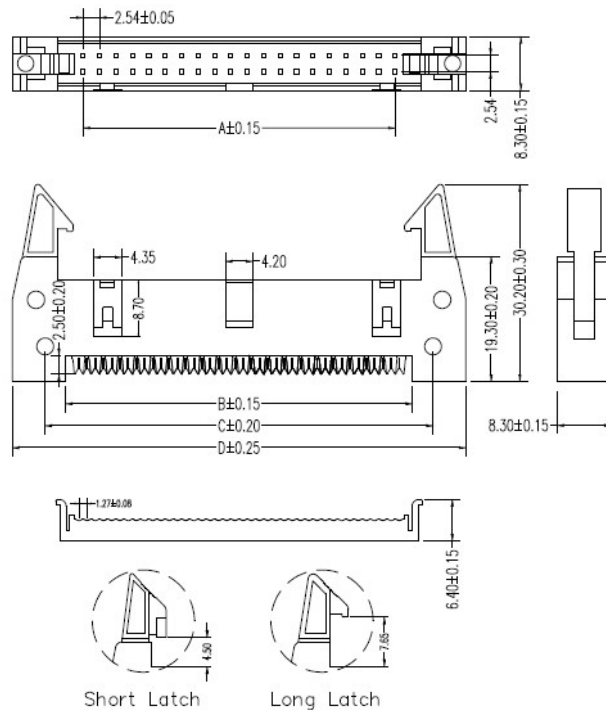

SPECIFICATIONS :

- Voltage Rating: 250V AC / DC
- Current Rating: 1A AC / DC
- Withstanding Voltage: 500V AC/minute
- Temperature Range: -40°C~+105°C
- Insulation Resistance: 1000MΩ Min.
- Contact Resistance: 20mΩ Max.

*Mates with LDZY A2544H series Housing

- Material:
- Wafer: PBT UL94V-0, Black/Grey
- Conductor: Brass/ Gold-Flash over the nickel

D2556 W V X 1-2NP-P0 XX X X
① ② ③ ④ ⑤ ⑥ ⑦ ⑧ ⑨ ⑩

- ① Series No.
- ② Category:W-wafer
- ③ Welding Board Angle: V- Straight 180° R-Vertical 90°
- ④ Colloid Feature: Blank-ordinary type, A-...
- ⑤ Soldering Type: 1-IDC Type
- ⑥ Circuit No.: 204-2x2PIN-264-2x32PIN
- ⑦ Material: P0-PBT UL94V-0,
- ⑧ Color: BK-Black,GY-Grey
- ⑨ Plating Method: T-Tin-plated, G-Gold-flash
- ⑩ Other Feature: A-Long Latch(7.65);BLANK-Short Latch(4.5)