
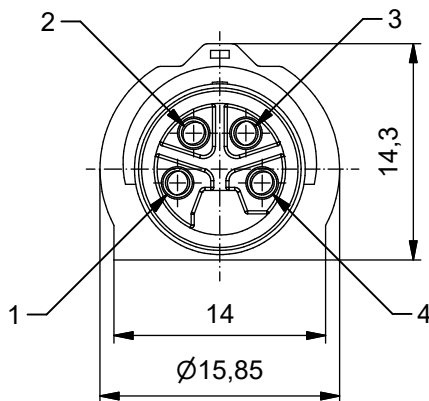
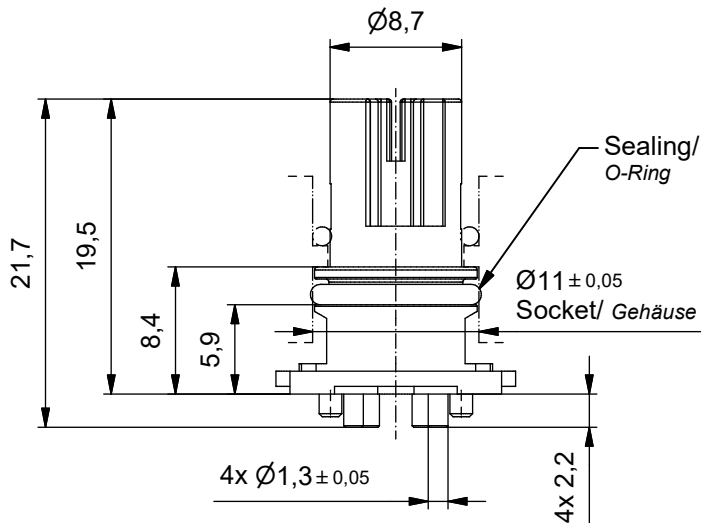


Tape & Reel -
parts with adhesive
pad Ø11mm
TR-Artikel mit
Klebspad Ø11mm

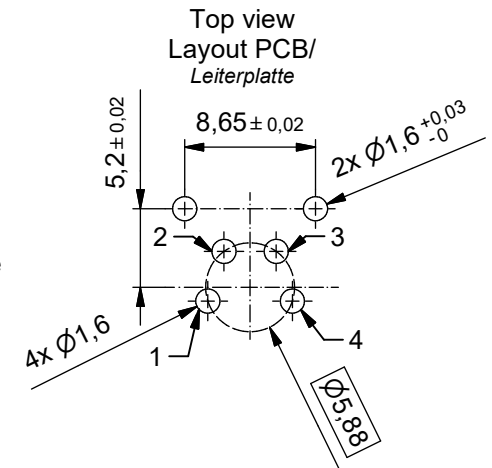

Technical specification/

Technische Daten:

Rated Voltage/ Bemessungsspannung:	63 V AC / 63 V DC
IEC 61076-2-111	
Current rating/ Strombelastbarkeit:	16 A / 40 °C
IEC 61076-2-111	
Insulation resistance/ Isolationswiderstand:	>=100 MΩ
IEC 60512	
Pollution degree/ Verschmutzungsgrad:	3/2
IEC 60664-1	
Degree of protection/ Schutzart:	IP 67, in mated condition/ im verschraubten Zustand
IEC 60529	
Temperature range/ Umgebungstemperatur:	-40 °C ... +105 °C
Mating cycles/ Steckzyklen:	>=100
IEC 60512-9a	

Materials/

Werkstoffe:

Contact/ Kontakt:	CuZn, Ni b / Au 0,2 gal.
Contact carrier/ Kontaktträger:	PA, UL 94 V-0
Sealing/ Dichtung:	FKM


Suitable for reflow soldering

max. 60s / 250°C

geeignet für Reflow Lötprozess

max. 60s / 250°C

Part no. packing unit Tape & Reel/ Art.-Nr. Verpackungseinheit Rolle:	Part no. packing unit in bulk/ Art.-Nr. Verpackungseinheit lose:	Description/ Beschreibung:	Pos/ Pol:
43-03907TR	43-03907	SAL- 12L - IKO4 / THR	4

 

dim. in mm

general tolerance/ Allgemeintoleranz:	0 ± 0,50 mm
	0,0 ± 0,25 mm
	0,00 ± 0,10 mm
	* ± 1,5°

	Date/Datum	Name
drawn/ gez.	28.10.2020	Bludau
appd./ gepr.	28.10.2020	Fischer

Female socket M12x1 L-coded THR 4pos.

Flanschkupplung M12x1 L-Codiert THR 4pol

Index: b Ä21-0446 09.12.21 ABL

scale/Maßstab:

CONEC®

dwg no /
Z.-nr.:

43K1A4668

DIN-
A4

RoHS compliant/konform

1 / 1