

SCMT13235

10 Piece 3/8" Drive Deep Socket Set

Barcode: 9311927132356

10 Metric Sockets
Deep: 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
Clips & Rail



SCMT13430

7 Piece 3/8" Drive Deep Socket Set

Barcode: 9311927134305

7 AF Sockets
Deep: 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"
Clips & Rail



SCMT13280

9 Piece 3/8" Drive In-Hex Socket Set

Barcode: 9311927132806

9 Metric In-Hex Sockets
Sizes: 3, 4, 5, 6, 7, 8, 9, 10, 12mm



SCMT13456

7 Piece 3/8" Drive In-Hex Socket Set

Barcode: 9311927134565

7 A/F In-Hex Sockets
Sizes: 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8"



Sockets Tru-Torque (Torx®)

Part No.	Barcode	Size
SCMT13375	9311927133759	T-27
SCMT13376	9311927133766	T-30
SCMT13377	9311927133773	T-40
SCMT13378	9311927133780	T-45
SCMT13379	9311927133797	T-50
SCMT13380	9311927133803	T-55



12 Point Spark Plug Sockets

Part No.	Barcode	Size
SCMT13435	9311927134350	5/8"
SCMT13436	9311927134367	13/16"



SCMT13904

Swiveling Head Ratchet

Barcode: 9311927139041

- Head can be pre-set to desired angle for access to hard to reach places
- When head is set "straight" the ratchet can be used like a screwdriver
- 72 Tooth gear for a small 5° arc swing
- Male
- 265mm



SCMT13906

Reversible Ratchet

Barcode: 9311927139065

- 30 Tooth mechanism for a 12° arc swing
- Quick-Release
- Male
- 195mm



SCMT13914

Rotator Dual Function

Barcode: 9311927139140

- Twist action handle for tight spaces
- Rotates with 0° swing
- 60 Tooth gear for a small 6° arc swing
- Dual Function
- Male
- 225mm

Rotator™


Continuous drive using twist action handle

Metric Inhex Sockets

Part No.	Barcode	Size
SCMT14280	9311927142805	6 x 60mm
SCMT14281	9311927142812	7 x 60mm
SCMT14282	9311927142829	8 x 60mm
SCMT14283	9311927142836	10 x 60mm
SCMT14284	9311927142843	12 x 60mm
SCMT14285	9311927142850	14 x 60mm
SCMT14286	9311927142867	17 x 60mm
SCMT14287	9311927142874	8 x 135mm
SCMT14288	9311927142881	10 x 135mm



AF Inhex Sockets

Part No.	Barcode	Size
SCMT14470	9311927144700	3/16" x 60mm
SCMT14471	9311927144717	7/32" x 60mm
SCMT14472	9311927144724	1/4" x 60mm
SCMT14473	9311927144731	9/32" x 60mm
SCMT14474	9311927144748	5/16" x 60mm
SCMT14475	9311927144755	3/8" x 60mm
SCMT14476	9311927144762	1/2" x 60mm
SCMT14477	9311927144779	9/16" x 60mm
SCMT14478	9311927144786	5/8" x 60mm



Spline Type Inhex Sockets

Part No.	Barcode	Size
SCMT14295	9311927142959	M6 x 60mm
SCMT14296	9311927142966	M8 x 110mm
SCMT14297	9311927142973	M10 x 110mm
SCMT14298	9311927142980	M12 x 110mm



12 Point Spark Plugs

Part No.	Barcode	Size
SCMT14445	9311927144458	5/8"
SCMT14446	9311927144465	13/16"



SCMT14904

BigFella Ratchet

Barcode: 9311927149040

- 36 Tooth mechanism for a 10° arc swing
- Quick-Release
- Male
- 425mm



SCMT14906

Reversible Ratchet

Barcode: 9311927149064

- 36 Tooth mechanism for a 10° arc swing
- Quick-Release
- Male
- 250mm




SCMT14907

Swivel Head Ratchet with T-Bar Handle

Barcode: 9311927149071

- 60 Tooth gear for a small 6° arc swing
- 180° Swivel head
- T Bar handle
- Male
- 340mm

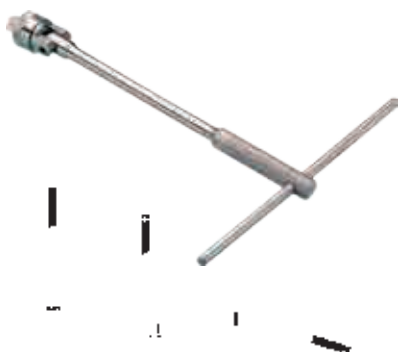

SCMT14919

Microtough Ratchet

Barcode: 9311927149194

- Smallest ratchet head in the industry providing access to confined areas
- 72 Tooth gear for a small 5° arc swing
- Reversible
- Male
- 250mm



SCMT14970

1/2" Drive Maintenance Free Pear Head Ratchet

Barcode: 9311927149705

- Fully Sealed Head
- Ergonomic Handle
- Maintenance Free
- Length: 262mm
- 72 teeth

