


Grey Thermoplastic Rubber Trolley Wheel 100mm, 80kg

Thermoplastic rubber-tyred wheel

PRODUCT

Article number

325-412-100R12

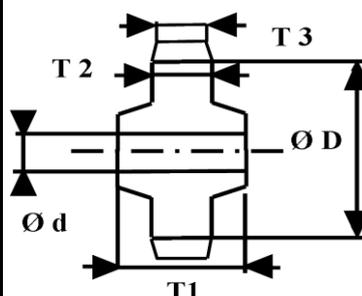

Product Details

Wheel Rim : made of grey impact-resistant polypropylene.

Tread : grey thermoplastic rubber, integrated type. Non-marking.

Hub : symmetrical with roller bearing.

Specifications

Wheel Diameter - ØD ± 1%	100 mm
Hub Type	Roller bearing
Hub Length T1	45 mm ±1
Width of Tread T2	32 mm ±1
Width of Tread-on floor T3	32 mm ±1
Axle Hole Ø d	Ø 12 mm
Hardness of tread A ±3	A 87° Shore
Load capacity	80 Kg
Temperature	-10 / +50 °C
Weight	0,16 Kg

TECHNICAL DATA

Applications :

Quiet and non-marking materials handling.

Lightweight, low starting effort.

Suitable for all interiors floors (warehouses, offices, shops, kitchens,...).