



Classic filament LED candles and lusters

Classic LEDLuster D 2.8-25W P45 E14 827 CL

Featuring a classic heritage design, Classic filament LED candles and lusters combine the familiar shapes of classic incandescent candle or luster with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light candles and lusters.

Product data

General Information	
Cap-Base	E14 [E14]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	2.8-25W
Light Technical	
Color Code	827 [CCT of 2700K]
Beam Angle (Nom)	270 °
Luminous Flux (Nom)	250 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	89.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz


Power (Nom)	2.8 W
Lamp Current (Nom)	15 mA
Wattage Equivalent	25 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	40 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Clear
Approval and Application	
Energy Efficiency Label (EEL)	A++

Classic filament LED candles and lusters

Energy Consumption kWh/1000 h	3 kWh
Product Data	
Full product code	871869977345800
Order product name	Classic LEDLuster D 2.8-25W P45 E14 827 CL
EAN/UPC - Product	8718699773458
Order code	929002391202

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002391202
Net Weight (Piece)	0.010 kg



Dimensional drawing

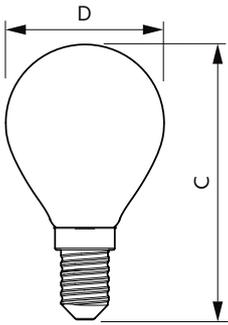

P45 230V 4-25W 250lm 2700K E14 D CL

Product	D	C
Classic LEDLuster D 2.8-25W P45 E14 827 CL	45 mm	82 mm


Photometric data

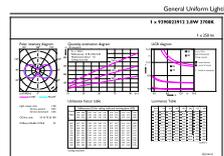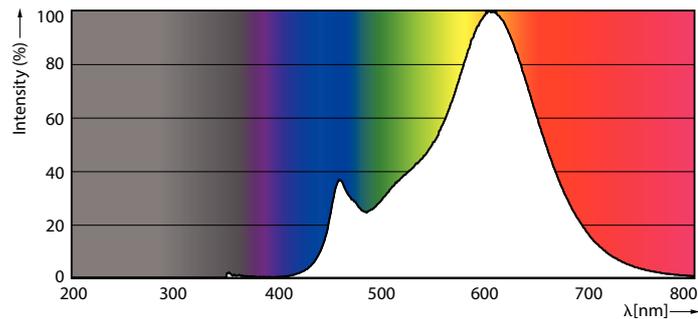

© 2020 Philips Lighting B.V. Page 1/1

LEDbulb CLA 4,5W A60 E27 827 CL


LEDbulb CLA 2,8W P45 E14 827 CL

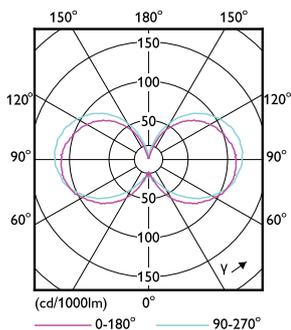


LEDbulb CLA WGD CRI90

Classic filament LED candles and lusters

Lifetime

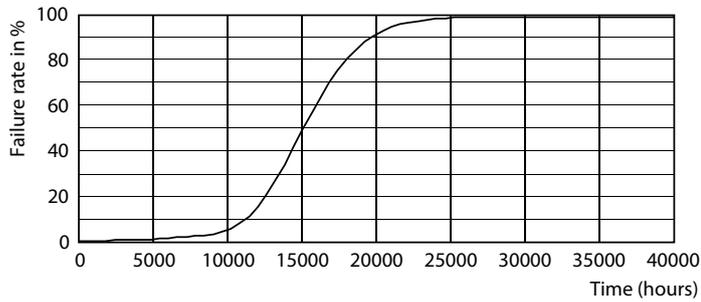

15K LED

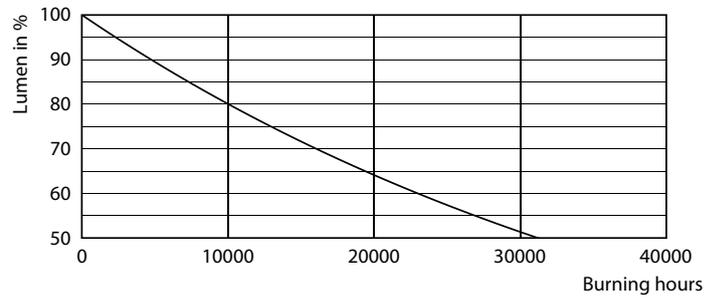

15K LMP

