



Brand of NTN corporation

Technical data

UKP313H

Bearing units




Grey cast housing, radial insert ball bearing with adapter sleeve, seal with slinger

KIT CONTENT

UK313G2H, P313

VISUAL (S)

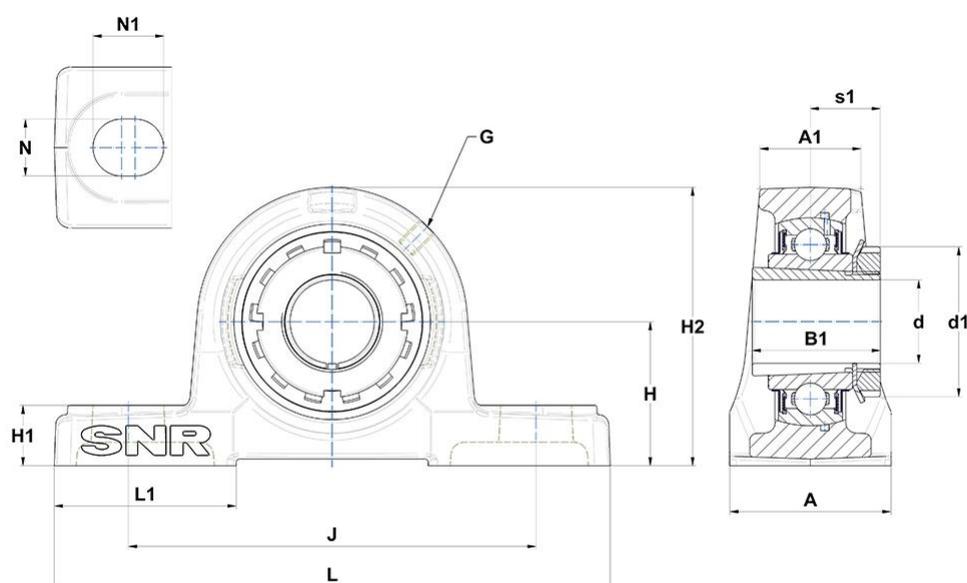

PRODUCT DEFINITION

Brand	SNR
A - Housing width	90 mm
A1 - Housing top width	57 mm
B - Width of Inner Ring	49 mm
d - Shaft diameter	60 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	85 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G - Grease fitting	M6x1
H - Distance mounting base to centerline spheric. seating diam.	90 mm
H1 - Housing foot height	33 mm
H2 - Housing height	176 mm
J - Mounting holes distance	260 mm
L - Housing length	340 mm
L1 - Housing foot length	105 mm
N - Mounting hole dimension	25 mm
N1 - Mounting hole length	38 mm
s1 - Distance nut to middle of bearing raceway	38,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	93860000 mN
C0 - Static load rating	60500000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	11 kg
Adapter sleeve designation	H2313

