

## Features

- 10" Device Compatibility

## RS PRO Server Rack Shelves

RS Stock No.: 0749258



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- *Racks are ideal products for ensuring the organized and secure mounting of equipment. They are commonly preferred in professional and industrial environments such as data centres, but their use may be limited in systems that require heavy load-bearing capabilities.*
- *These racks are suitable for servers, network devices, and electronic equipment, and can be integrated with other mounted accessories.*

## General Specifications

<b>Type</b>	2 POINT CONNECTED RACK MOUNT SHELVES
<b>Rack Units</b>	1U
<b>Material</b>	Steel
<b>Base Material</b>	Metal
<b>Weight Capacity</b>	20Kg
<b>Rack Type</b>	2 Point
<b>Rack Hole Type</b>	M6 Threads
<b>Colour</b>	RAL9005
<b>Extension Type</b>	Fixed
<b>Paint Texture Type</b>	Textured
<b>Compatible Rack Size</b>	10" Rack
<b>Surface Finish</b>	Electrostatic Powder Coating


## Mechanical Specifications

<b>Dimensions</b>	254.00mm x 150.00mm
<b>Height</b>	44.00mm
<b>Width</b>	254.00mm
<b>Depth</b>	150.00mm
<b>Depth Type</b>	Non-Adjustable
<b>Material Thickness</b>	1.2mm
<b>Weight</b>	0.44kg


## Similar Products

Stock No.	Brand	Rack Units	Material	Colour	Measurements
<b>0749232</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 200.00mm
<b>0749233</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 250.00mm
<b>0749234</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 300.00mm
<b>0749235</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 400.00mm
<b>0749236</b>	RS PRO	2U	1.2mm Steel	RAL9005	H: 88.00mm D: 350.00mm
<b>0749237</b>	RS PRO	2U	1.2mm Steel	RAL9005	H: 88.00mm D: 550.00mm


Front View

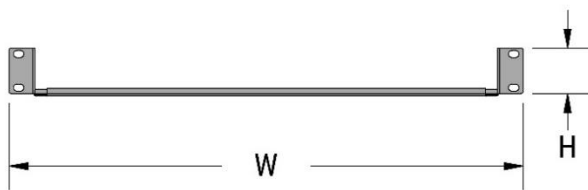

Side View

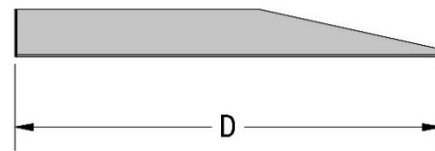

Top View

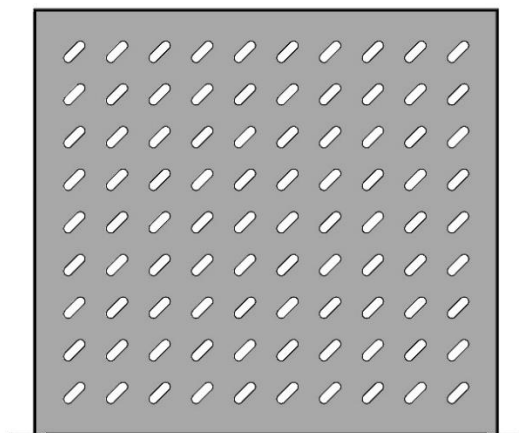

Bottom View

