




LED FIL C40 GS8 E14 DIM 4W (32W) 350lm 827 Frosted

Article number: 147024

BAI LED Filament Dimmable Candle C40 GS8 E14 4W 2700K Frosted 350lm (32W) 230V-240V 320° 40x130mm B35 LED-lamp

LED filament bulbs are a smart and eco-friendly alternative to traditional incandescent and halogen lights. They use less energy and last significantly longer. This elegant LED candle bulb, featuring beautifully frosted and twisted glass, is ideal for classic chandeliers and adds instant charm and sophistication to any interior.

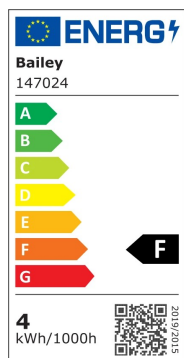

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL C40 GS8 E14 DIM 4W (32W) 350lm 827 Frosted
Brand	Bailey
Productseries	LED Filament candle
Producttype	C40 E14 827 FR

ETIM specifications

Socket	E14
Luminous flux [lm]	350 - 350
Nominal voltage [V]	220 - 240
Lamp power [W]	4 - 4
Colour temperature [K]	2700 - 2700
Diameter [mm]	40
Length [mm]	130
Dimmable	Yes
Lamp shape	Candle
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	350
Power factor	0.9
Lamp efficacy [lm/W]	88
Nominal current [mA]	20 - 20
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Other
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	4
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Glass

Complementary articles



142061
Lampholder Metal Screw E14
Chrome



142062
Lampholder Metal Screw E14
Black