


78 03 140

Electronic *Super Knips*® XL



- For ultra fine cutting work, e.g. in electronics and fine mechanics
- In particular for cutting cable ties to length
- Ground, very sharp cutting edges without bevel
- Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life
- Precision shaped tips cut wires resting on a board from 0.2 mm dia.
- Joint with stainless steel rivet
- Extremely smooth movement for minimum operator fatigue
- With opening spring and opening limiter
- Cutting edge hardness approx. 54 HRC
- INOX - tool steel

Article No.	78 03 140
EAN	4003773081678
Pliers	
Head	polished
Handles	with multi-component grips
Cutting capacities medium hard wire (diameter) Ø mm	1,2
Cutting capacities soft wire (diameter) Ø mm	0,2 - 2,1
B mm	12,3
D mm	9,2
A mm	15,7
Length mm	140
Net weight g	77

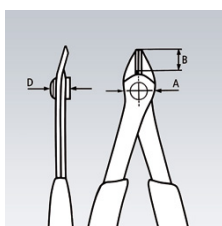

for flush cutting, e.g. for shortening cable ties

technical change and errors excepted