

The Robust

Composition: 100% natural rubber

Applications:

heavy duty and anti-slip applications in the areas to be secured

Environment: dry or wet

Advantages:

- draining thanks to its pinned backing
- antislip
- flexible
- easy to clean
- ultra sturdy
- self-weighted
- reassuring
- sound-proofing
- thermal insulation
- sound-proofing

Color: black

+ Info:

- flexibility obtained by the material
- cutting on request



M69




M69 PLUS
Upper surface




M69 PLUS
Lower surface




M69 Upper surface

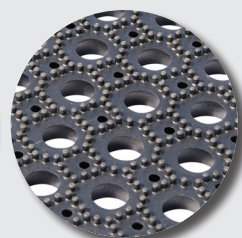

M69 Lower surface

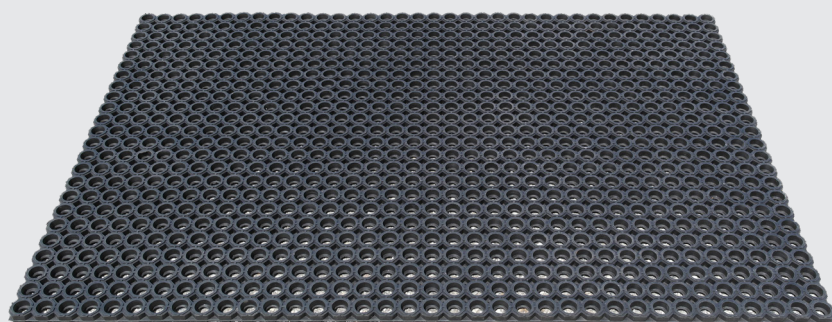

M69+

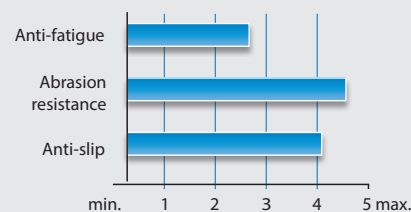

Reference	Dimensions	Thickness	Weight	Fire classification
M69	100 x 150 cm	23 mm	18,0 kg/p	-
M69CFL	100 x 150 cm	23 mm	18,5 kg/p	Cfl-S1
M69PLUS	100 x 150 cm	23 mm	18,0 kg/p	-
M69PLUS-BFL	100 x 150 cm	23 mm	21,5 kg/p	Bfl-S1
C68	Junction for M69		0,03 kg/p	

