


FILTRAZIONE PREVOST - GRUPPI DI TRATTAMENTO

Filtro-regolatore del lubrificatore - 3 moduli

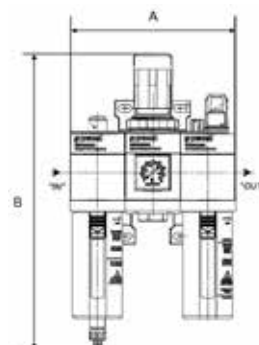

Pressione max. di utilizzo
10 bar

Filtrazione (µm)
25.00

Codice	Maschiatura	Portata a 6 bar (l/min) (ΔP= 1.00 bar)		Peso netto (Kg)	Dim. A (mm)	Dim. B (mm)
ATU T2510100	G1/8	500	0.5 / 10	0.977	97	302
ATU T2510101	G1/4	800	0.5 / 10	0,977	97	302
ATU T2510102	G3/8	2200	0.5 / 10	2,446	97	302
ATU T2510103	G1/2	3500	0.5 / 10	2.446	97	302