

FEATURES

- Versatile and easy to fit
- Can be screwed into place and removed manually
- Hexagonal shaped versions can be tightened using a wrench
- Lock PCB securely into place
- Nylon insulation material reduces the risk of electrical short circuits and is also lightweight and durable.
- Versions with nickel plated brass threaded inserts for resistance to corrosion

RS PRO Nylon Round Standoff Male/Female, 25mm, M6 x M6

RS Stock No.: 653-9497



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS Pro a range of high-quality standoffs made from solid nylon or with metal threaded inserts and a nylon insulation material. These versatile standoffs are designed to mount and secure your PCB as well as elevating your PCB from other components such as the inside of a computer chassis or another PCB, similar to spacers. They are also ideal for improving airflow space around components when the equipment becomes hot. These stand-offs are available in a range of different heights and threads sizes to suit a wide range of applications.

General Specifications

Gender Type	Male/Female
Material	Nylon
Body Shape	Round
Finish	Plain
Application	Office machinery, Telecommunications equipment, Consumer electronics, Audio visual equipment

Mechanical Specifications


Body Length	25mm
Thread Size	M6 x M6
Stud Length	12.7mm
Thread Size A	M6
Thread Size B	M6
Outside Diameter	12.7mm
Hole Depth	12.7mm

Approvals

Compliance/Certifications	EN61340
----------------------------------	---------



TYPE 1

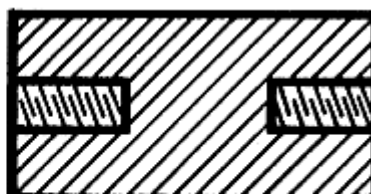

TYPE 2