



PRODUCT DATASHEET

Lenina series

last update 5/2/2015

DETAILS

Product Number	C12606_LENINA-DL
Family	Lenina
Type	Sublens
Color	clear
Diameter	73.98 mm
Height	4.91 mm
Style	round
Optic Material	PC
Holder Material	
Fastening	
Status	ready
ROHS Compliant	Yes
Date Updated	5/02/2015




OPTICAL PROPERTIES

LED	Viewing Angle	Light Beam	Efficiency	cd/lm	Connector
	N/A deg	Diffuser	-	sim: 0.000	-


H G F E D C B A

4


4

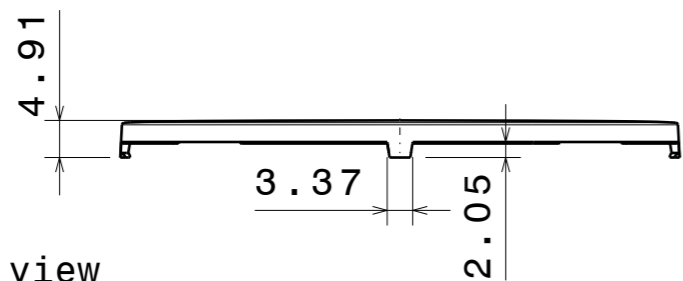

Front view

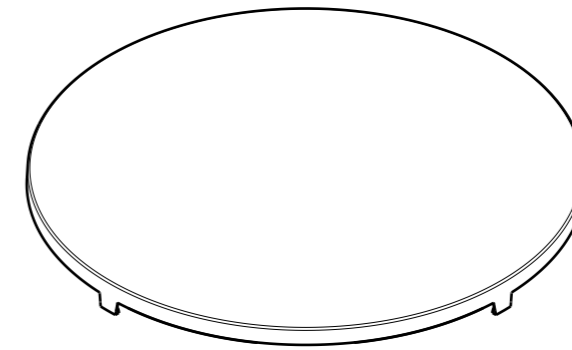

Isometric view

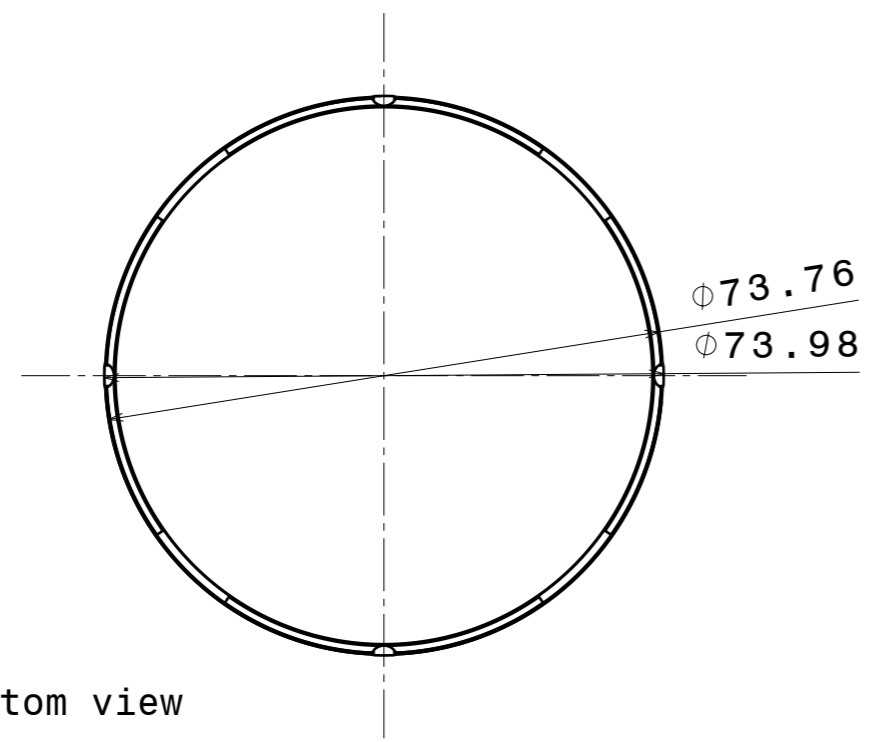

Bottom view

3

3

2

2

INDEX	PART NO	DESCRIPTION	MATERIAL	COLOUR
1	C12606	LENINA-DL	PC	clear

Tolerances if not otherwise shown
According to DIN ISO 2768-1
Linear measures: class C
According to DIN ISO 2768-2
Form and position: class L

LEDiL LediL Oy
Salorankatu 10
FIN 24240 SALO
Finland

THIRD ANGLE PROJECTION:

DRAWING TITLE
C12606_LENINA-DL

This drawing is the property of LEDiL Oy. It may not be reproduced, copied or communicated without a written agreement with LEDiL Oy.

SIZE	PART NUMBER
A3	C12606

SCALE	1:1	WEIGHT	9,07 g	SHEET	1/1
-------	-----	--------	--------	-------	-----

1

1

H G F E D C B A

NOTE: The typical divergence will be changed by different color, chip size and chip position tolerance. The typical total divergence is the full angle measured where the luminous intensity is half of the peak value.