

**C58BC-W2,1
4C/A+SVR**

Comprehensive workbench, 2.1 m long, with 4 drawers

Main features:


- Worktop (2,100x750 mm) made from multi-ply wood, 38 mm thick
- 4 drawers (367x588 mm) with ball bearing slides:
 - 2 drawers 70 mm high
 - 2 drawers 140 mm high.
- Drawer bases protected by foamed rubber mats
- Each drawer can accommodate up to 4 EVA foam or ABS thermoformed trays
- Front centralized lock
- Steel frame with 2 supporting legs
- Holes for a vice (1599F/150 - 1599GI/150, to be ordered separately)
- 2 lower half-shelves for objects, 1,788x335 mm; thickness: 40 mm
- Static load capacity: 800 kg, evenly distributed
- Can be fixed to floor

Kit with 4 perforated tool panels, comprising the following:

- 3 supporting brackets
- 6 400-mm uprights
- 2 1,015-mm supports; can accommodate 1 19" rack multi-socket (not included)
- 4 perforated tool panels 1,015x25x400 mm

 146 kg

2.100x750x1.860 mm

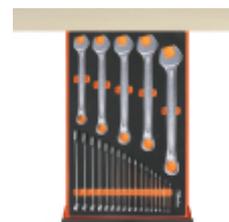

		art.
	058000727	C58BC-W2,1 4C/A+SVR