



Technical data

HK2220LL/3AS

Drawn cup needle roller bearings, opened end

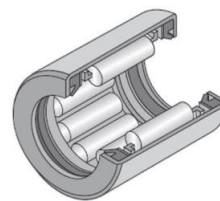

VISUAL (S)

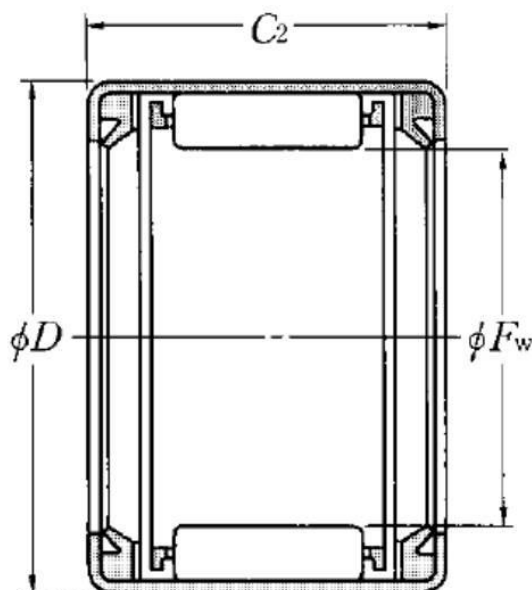

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	22 mm
D - External diameter	28 mm
C2 - Width of the drawn cup LL	20 mm
C3 - Max drawn cup closed end thickness LL	2,7 mm
Lubrication hole on outer ring	Non/No
Inner ring reference	IR17X22X23
Mass	0,026 kg



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

HK2220LL/3AS

Drawn cup needle roller bearings, opened end

PRODUCT PERFORMANCE

Cr - Dynamic load rating	13,6 kN
C0r - Static load rating	22,1 kN
N lim - Grease lubrication limit speed	7500 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	100 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	HK2220LL/3AS
Image	NRBHK_LL_1.jpg, NRBHK_LL_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15