


RoBust LED Headlight 6W 6500K 550lm IP54 5V CLIII

Article number: 147110



BAI RoBust LED Headlight 6W 6500K 550lm IP54 CLIII Rechargeable 5V/1A 3.7V 1200mAh 66x53x43mm Black housing with orange rubber Elastic headband Switch 550lm/300lm/S.O.S. + 0.5M USB-C charging cable

Bailey RoBust Headlamp – powerful light, hands-free comfort. The RoBust headlamp is part of the popular Bailey RoBust LED Charge series and is designed to deliver excellent visibility while keeping both hands free. Perfect for working in dark environments where precision and convenience matter. Equipped with a motion sensor, the headlamp can be switched on or off not only via the button, but also with a simple hand movement in front of the lamp. It features three lighting modes: 550 lumens, 300 lumens, and a flashing S.O.S. mode. The elastic headband is easy to adjust and suitable for both head and helmet use. Charging is quick and simple using the included USB cable. Depending on the selected mode, a fully charged lamp delivers 3.5 to 7 hours of bright 6500K white light. Durable, practical and ready for action.

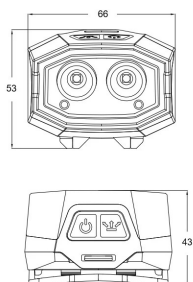

General ETIM properties

ETIM group	Luminaires
ETIM class	Flashlight
Name	RoBust LED Headlight 6W 6500K 550lm IP54 5V CLIII
Brand	Bailey
Productseries	RoBust LED charge
Producttype	HEADLIGHT 6W USB

ETIM specifications

Material	Plastic
Model	Headlight
Luminous flux adjustable	Positions
Luminous flux [lm]	300 - 550
Length [mm]	66
Rechargeable	Yes
Battery type	Built-in battery (rechargeable)
Housing colour	Orange
Degree of protection (IP)	IP54
Batteries included	Yes
Lamp type	LED not exchangeable
With light source	Yes
Weight total [g]	91
Number of batteries	1

Complementary articles



145894
Charger 10 USB-A Ports



147138
Charging Hub 10 USB-A & 10
USB-C Ports