


Wall passage

Wall passage stainless steel

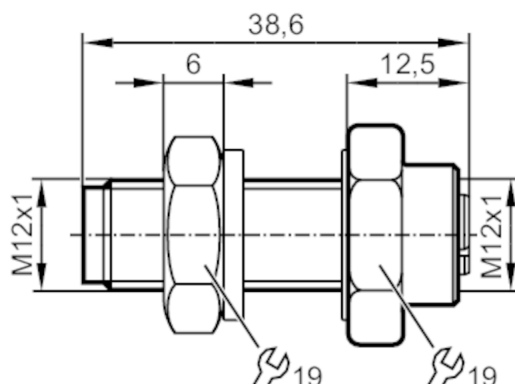

Electrical data

Operating voltage	[V]	< 60 AC/DC
Max. current load total	[A]	8; (pin 1+3: 4 A; pin 2+4: 4 A)

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 65; IP 67; IP 69K

Mechanical data


Weight	[g]	29.5
Materials		stainless steel (303/1.4305); Sealing: EPDM
Moulded-body material		stainless steel (303/1.4305)
Tightening torque	[Nm]	1

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: stainless steel (303/1.4305)

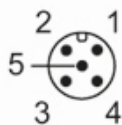


E73009



Wall passage

Wall passage stainless steel

Connection

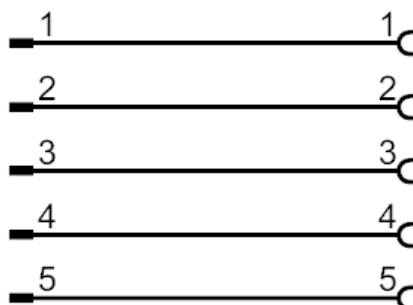

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: stainless steel (303/1.4305)

