

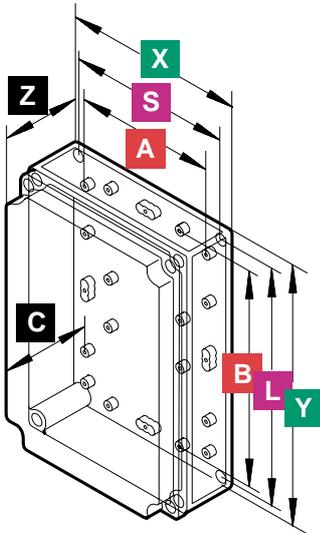


- Y** External height
- X** External width
- Z** External depth
- C** Free internal mounting height
- B** Mounting plate assembly
- A** Mounting plate assembly
- L** Wall mounting
- S** Wall mounting

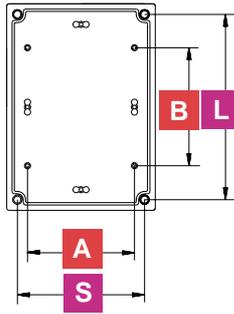

FP 10674 fastening lug measures

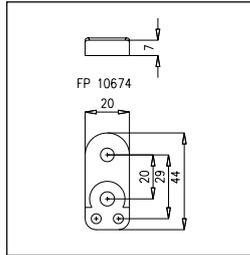

SYMBOLS AND ABBREVIATIONS

MI 100 / 75 T

- Cover G = Grey  
T = Clear cover transparent
- Total height = base 50 mm + cover 25 mm
- Size (length + width/2)
- Enclosure range/type

MO	MONO smooth sides
MI	MINI MI sides with PG knockouts/small and large
PC	MINI with smooth sides
UL PC	UL listed MI
UL PC	UL listed PC


UL LISTING

Underwriters Laboratories (UL) Inc. is an independent testing laboratory which issues product safety standards and through rigorous testing, verifies that product performance complies with the applicable standard. Further, UL monitors on-going product production to assure continued compliance with the applicable standard. For enclosures, UL has issued two standards, UL 50 and UL 508. Fibox voluntarily submits its enclosure products to Underwriters for evaluation and listing to these standards. Those products complying with the standard are permitted to display the UL Listing Mark. All Fibox UL listed products are also CNL listed for use in Canada.

**UL LABELLING ON REQUEST**



# FIBOX MINI WITH PG KNOCK-OUTS

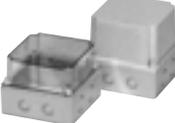FIBOX MINI PG POLYCARBONATE PC: IP 66 / IP67, IK 08/IK 07	<b>Z</b> mm	<b>C</b> mm	Including: Enclosure base, cover with EPDM or PUR gasket, 4 cover screws, and mounting plate screws.				<b>B</b> x <b>A</b>
			ORDER SYMBOL		ORDER SYMBOL	<b>L</b> x <b>S</b> mm	
			Grey cover				Transparent cover
<b>MI 100</b> <b>Y</b> x <b>X</b> 125 mm 75 mm 	75 100 125	62 87 112	MI 100/75 G MI 100/100 G MI 100/125 G		MI 100/75 T MI 100/100 T MI 100/125 T	B x A 90 x 40  L x S 107 x 57	
<b>MI 125</b> <b>Y</b> x <b>X</b> 125 mm 125 mm 	75 100 125	62 87 112	MI 125/75 G MI 125/100 G MI 125/125 G		MI 125/75 T MI 125/100 T MI 125/125 T	B x A 90 x 90  L x S 107 x 107	
<b>MI 150</b> <b>Y</b> x <b>X</b> 175 mm 125 mm 	75 100 125 150	62 87 112 137	MI 150/75 G MI 150/100 G MI 150/125 G MI 150/150 G		MI 150/75 T MI 150/100 T MI 150/125 T MI 150/150 T	B x A 140 x 90  L x S 157 x 107	
<b>MI 175</b> <b>Y</b> x <b>X</b> 175 mm 175 mm 	75 100 125 150	62 87 112 137	MI 175/75 G MI 175/100 G MI 175/125 G MI 175/150 G		MI 175/75 T MI 175/100 T MI 175/125 T MI 175/150 T	B x A 5.5 x 5.5 140 x 140 L x S 6.2 x 6.2 157 x 157	
<b>MI 200</b> <b>Y</b> x <b>X</b> 250 mm 175 mm 	75 100 150	62 87 137	MI 200/75 G MI 200/100 G MI 200/150 G		MI 200/75 T MI 200/100 T MI 200/150 T	B x A 140 x 215  L x S 232 x 157	

External height **Y** External width **X** External depth **Z** Free internal mounting height **C** Mounting plate assembly **B** x **A** Wall mounting **L** x **S**