


EXPERT Riveting hammers



Description:

- ISO 15601
- Head hardness 50-58 HRC.
- Handle-blade connected by clasp.
- Hickory handle.
- Domed head.

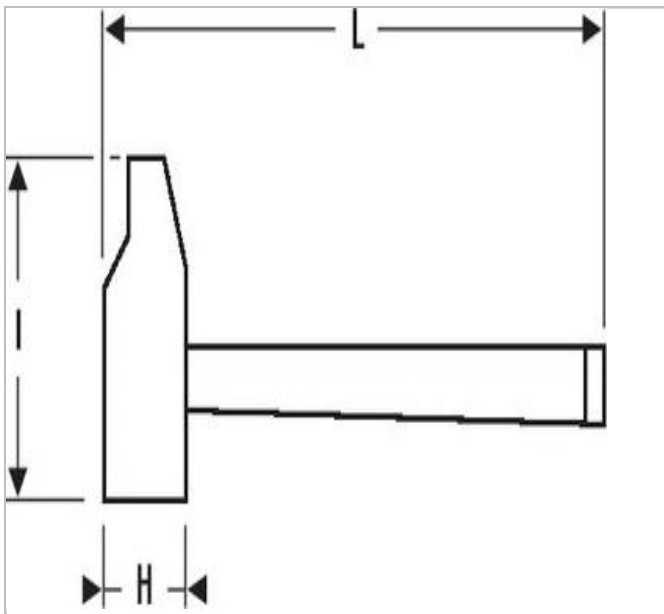

	Length L [mm]	Width I [mm]
E154665	284	78,5
E154667	304	91,5
E154668	306	98
E154669	309	104
E154670	325	108,5
E154672	355	126
E154673	365	135,5
E154674	370	141