



2690Z0

HeadsUp Lite™

Headlamp

Regardless of the job, the 2690Z0 HeadsUp Lite™ won't leave you in the dark. With 74 lumens of LED light, 11 hours of battery run time and weighing in at 116 gr (4.1 ounces), it's brighter, more efficient, compact and lighter than other headlamps in its class. The no-nonsense rotary bezel switch is easy to operate, even when wearing bulky gloves.

The 2690Z0 is made of impact and chemical resistant Anti-static Impact Modified PC/PBT and it's water resistant for all-weather use. It comes with an adjustable and comfortable cloth strap, as well as a heavy duty rubber strap that will not slip off your helmet. Being certified to ATEX safe for use in high-risk hazardous locations, Zone 20 areas, the 2690Z0 HeadsUp Lite™ is ideal for professionals who work in chemical, pharmaceutical, power, oil and gas, and fire rescue industries. Get the 2690Z0 HeadsUp Lite™ from Peli.



DIMENSIONS

Length	2.81" (7.1 cm)
---------------	----------------

MATERIALS

Body	Anti-static Impact Modified PC/PBT
O-Ring	EPDM
Lens	Polycarbonate (PC)
Shroud	Anti-static Impact Modified PC/PBT
Contact Spring Retainer	Nickel-Plated Phosphore Bronze

COLOURS

 Black

LIGHT SPECS

Lamp Type	LED
Lamp Life	10000 hrs

POWER

Battery Size	AAA
Battery Type	Alkaline
Battery Quantity	3
Batteries Included	yes
Volts	4.5v

WEIGHT

Weight With Batteries	4.1 oz (116 gr)
------------------------------	-----------------

Weight Without Batteries

2.8 oz (79 gr)
c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999
info@peli.com • www.peli.com

Peli

SWITCH

Document created on 05-09-25

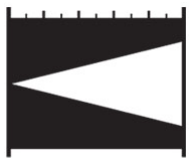
Switch Type One-handed Rotary Switch
Light Modes On / Off

CERTIFICATIONS

ATEX Zone 0

OTHER

Minimum Pack 1
Package Code C

FL1 STANDARD	HIGH
	74 LUMENS
	11h 0mins
	92m
	2124cd
	IPX7

ACCESSORIES