



Brand of NTN corporation


Technical data

BBER16UU

Flange type ball bushings



VISUAL (S)

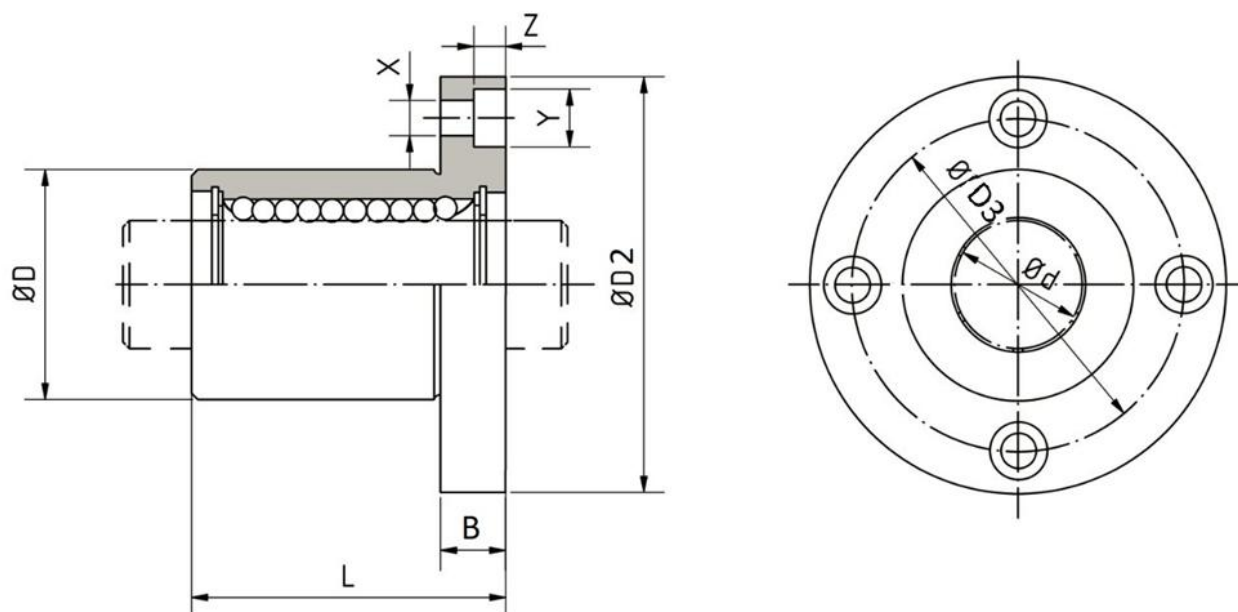

PRODUCT DEFINITION

Brand	SNR
Design type	BBER
Ball bushings category	Flange type ball bushings
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	16 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0,009/-0,001
D - External diameter	26 mm
D - External diameter tolerance	0/-0,016
L - Length	36 mm
L - Length tolerance	0,3/-0,3
B - Flange width	6 mm
D2 - Diameter	46 mm
D3 - Diameter	36 mm
X	4,5 mm
Y	7,5 mm
Z	4,1 mm
Maximum eccentricity	0,012 mm
Number of ball rows	4
Mass	0,103 kg

PRODUCT PERFORMANCE	
Cmin	0,432 kN
Cmax	0,611 kN
C0min	0,892 kN
C0max	1,261 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BBER16UU



BBER16UU

Flange type ball bushings

ESHOPDONOTDISPLAY	
Image	BBER_1.JPG, BBER_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15