

## DATASHEET




**UNDKIT3BCWW**

**UNDKIT3BCCW**

**Dimmable Under Cabinet  
LED Light Kit**

[www.mlaccessories.co.uk](http://www.mlaccessories.co.uk)

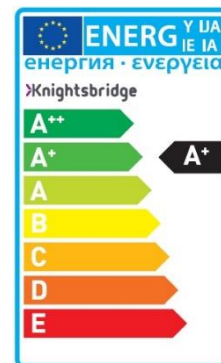

MLA PART CODE	UNDKIT3BCWW	UNDKIT3BCCW
DESCRIPTION	Under Cabinet LED Light Kit – pack of 3 with Dimmable Driver and 6-Way Connector	
FINISH	Brushed Chrome	
NETT WEIGHT (KG)	0.37	
DIMENSIONS (MM)	Diameter – 68 Projection – 11	
CUT-OUT (MM)	63	
FIXING CENTRES – SURFACE (MM)	48	
WATTAGE (W)	2.5 (per lamp)	
LUMENS (LM)	185 ±5% (per lamp)	220 ±5% (per lamp)
EFFICACY (LM/W)	52 (kit of 3)	62 (kit of 3)
CCT	3000K	4000K
LED COLOUR	Warm White	Cool White
CRI	>80	
CIRCUIT WATTAGE (W)	9 (driver with 3 lamps)	
RUNNING CURRENT (A)	0.04	
POWER FACTOR	0.89	
BEAM ANGLE	90°	
LIFE SPAN (HRS)	15,000	
INPUT VOLTAGE	Mains 230V 50Hz	
CONSTRUCTION	Polycarbonate and Aluminium	
CABLE LENGTH (MM)	2,500	
CLASS	Class II	
IP RATING	IP20	
DIMMABLE	Yes, Trailing edge only	
WARRANTY	3 Years	
ORIGIN OF MANUFACTURE	China	
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes	
MANUFACTURED IN ACCORDANCE WITH	BS EN 60598	
EAN	5056270805543	5056270805567

AVAPR20\_V1