

# ToLEDo GLS 1521LM 827 B22 SL4


Item No: 0029640



Compact and elegant design Suitable replacement for halogen, incandescent and compact fluorescent lamps Instant light at the flick of a switch Uniform light distribution Good colour rendering (CRI 80) Perfect for hotels, restaurants, lobbies, corridors, stairwells, reception areas Lower maintenance costs 12,000 hours average rated life

## Technical Assets

### Dimensions (mm)

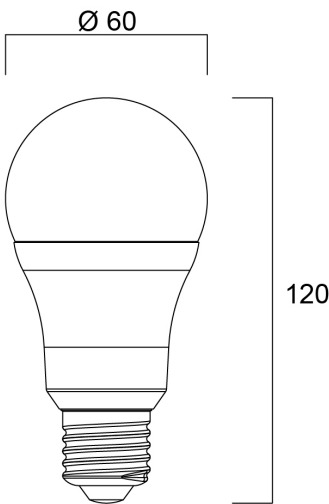

### Photometrics

# ToLEDo GLS 1521LM 827 B22 SL4

Item No: 0029640



## General data

|                                         |                                  |
|-----------------------------------------|----------------------------------|
| Product name                            | ToLEDo GLS 1521LM<br>827 B22 SL4 |
| Technology                              | LED                              |
| Watt (Rated) (W)                        | 13                               |
| Cap/Base                                | B22                              |
| Fixture rating                          | Open                             |
| General application                     | Residential & Consumer           |
| Operating temperature range (°C)        | -20°C...+40°C                    |
| Performance ambient temperature Tq (°C) | 25                               |
| ETIM Class                              | EC001959                         |
| Warranty                                | 2 years                          |

## Optical data

|                                              |           |
|----------------------------------------------|-----------|
| Useful luminous flux (Φuse)                  | 1521      |
| Luminous flux (Rated) (lm)                   | 1521      |
| Correlated colour temperature (k)            | 2700      |
| Light colour                                 | Homelight |
| CRI (Ra)                                     | 80        |
| Colour Variation Initial (SDCM)              | SDCM6     |
| Photobiological Risk Group                   | RG0       |
| Lumen maintenance at end of nominal life (%) | 70        |

## Electrical data

|                                                   |         |
|---------------------------------------------------|---------|
| Power consumption (W)                             | 13      |
| Wattage (W)                                       | 13      |
| Equivalent watt (W)                               | 100     |
| Primary Supply/Product voltage - min (V)          | 220     |
| Primary Supply/Product voltage - max (V)          | 240     |
| Control gear required                             | No      |
| No. Of switching cycles before premature failures | >100000 |
| Dimmable                                          | No      |
| Inrush Current (A)                                | 6       |
| Inrush Duration (µs)                              | 350     |
| Lamp Energy Label (class)                         | E       |
| Nominal Frequency (Hz)                            | 50/60Hz |
| Max. products per 16A C Breaker                   | 27      |
| Max. products per 16A B Breaker                   | 13      |

## Lifetime data

|                            |       |
|----------------------------|-------|
| Lifespan L70 B50           | 12000 |
| Average life (Nominal) (h) | 15000 |
| Average life (Rated) (h)   | 15000 |

## Physical data

|                               |       |
|-------------------------------|-------|
| Nominal Product Length (mm)   | 118   |
| Nominal Product Diameter (mm) | 60    |
| Weight (kg)                   | 0.182 |

# ToLEDo GLS 1521LM 827 B22 SL4

Item No: 0029640



## Packaging

|                                       |                |
|---------------------------------------|----------------|
| Product EAN number                    | 5410288296401  |
| Packaging single length / height (cm) | 21.2           |
| Packaging single width (cm)           | 6.1            |
| Packaging single depth (cm)           | 12.3           |
| DUN14 (inner)                         | 15410288296408 |
| Units per outer package               | 6              |
| Packaging outer length / height (cm)  | 37.9           |
| Packaging outer width (cm)            | 22.1           |
| Packaging outer depth (cm)            | 13.4           |

## Safety data

|                                     |                                            |
|-------------------------------------|--------------------------------------------|
| Optimal operating condition (°C)    | -20-40                                     |
| Breakage cleaning instructions      | Not applicable                             |
| Special purpose lamp                | No                                         |
| Dry applications use only           | Yes                                        |
| Suitable for household illumination | Yes                                        |
| Safety message                      | Not Suitable for totally enclosed fixtures |