

V-FIT™ Harness

Technical Data Sheet



CAPACITY	140 Kg
BRAND	MSA
SUB BRAND / MODEL NAME	V-FIT
SIZES	Extra Small, Standard, Extra Large
D-RING LOCATIONS	Dorsal (back), chest, belly, hips (depends on version)
BUCKLE CONNECTION	Bayonet
PADDING LOCATIONS	Shoulder, Legs, Waist (depends on version)
RFID EQUIPPED	Yes (inside label pack)
THREAD / STITCHING	Polyester
WEB	Polyester, nano-technology treated
WEB KEEPER	Polyester, hook and loop closure
LEG BUCKLES	Anodized forged aluminum, stainless steel tabs and adjuster
CHEST BUCKLE	Anodized forged aluminum, stainless steel tabs and adjuster
D-RING	Anodized forged aluminum
PFL ADAPTER	Integrated polymer dedicated PFL attachment point
PADDING	Breathable spacer mesh and foam, removable
PRODUCT WEIGHT	1,90 Kg (version without waist belt) 3,00 Kg (version with waist belt)
PRODUCT STYLES	Racing style
LANYARD KEEPERS	2 at the front, 2 at the waist
FALL INDICATOR	Dual, at the backside
OPERATING TEMPERATURE	-40°C... +50°C
MAXIMUM LIFESPAN	10 years from date of first use
STANDARDS	EN 361:2002, EN 358:2018 (depends on version)




front



back

Harness Size Chart

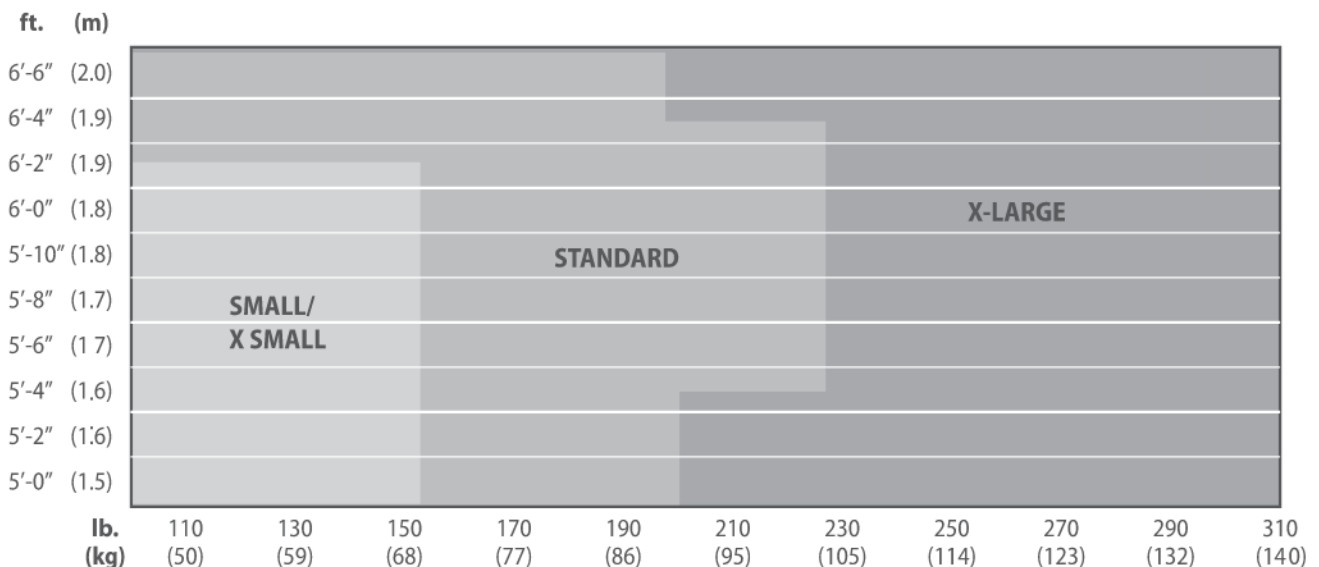

WE KNOW WHAT'S AT STAKE.