


Geberit Mapress Copper adaptor union with male thread

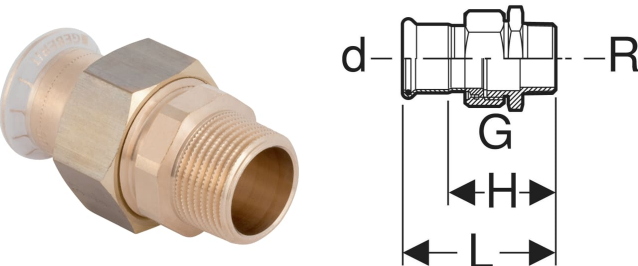

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For compressed air (oil purity class 0–3)
- For negative pressure

- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Union nut made of brass
- Seal ring made of CIIR, black

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	Gunmetal / lead-free gunmetal

Art. no.	DN	d _ø mm	R ″	G ″	Product material	L cm	H cm
65531	10	12	3/8	1/2	Gunmetal	5.1	3.4
65540	10 / 15	12	1/2	1/2	Gunmetal	5.5	3.8
65532	12 / 15	15	1/2	3/4	Lead-free gunmetal	6.1	4.1
65541	12 / 20	15	3/4	3/4	Lead-free gunmetal	6.3	4.3

Art. no.	DN	d _ø mm	R "	G "	Product material	L cm	H cm
65533	15	18	1/2	3/4	Lead-free gunmetal	6.1	4.1
65542	15 / 20	18	3/4	3/4	Lead-free gunmetal	6.3	4.3
65534	20 / 15	22	1/2	1	Gunmetal	6.7	4.6
65543	20	22	3/4	1	Gunmetal	6.8	4.7
65544	20 / 25	22	1	1	Gunmetal	6.9	4.8
65535	25	28	1	1 1/4	Lead-free gunmetal	7.5	5.2
65536	32	35	1 1/4	1 1/2	Lead-free gunmetal	8	5.4
65537	40	42	1 1/2	1 3/4	Lead-free gunmetal	8.5	5.5
65538	50	54	2	2 3/8	Gunmetal	9.7	6.2