

# Data sheet Indicator 22 mm.


Part No.: 82-6152.01A4

## Technical data




Terminal	Screw terminal
Shape of illumination	Ring
Operating voltage	24 V AC/DC
Operation current	7 mA
Lens illumination	illuminative
Lens colour	Silver
Lens shape	flush
Lens material	Stainless steel
Lens optics	opaque
Front bezel shape	flush
Front bezel material	Stainless steel
Weight	0.018 kg
Illumination colour	Red / Green
Kind of illumination	Bi-colour-LED
Operating temperature	- 30 °C ... + 70 °C
Approbations	CB, CCC, C UL, UL
Climate resistance	Damp heat, 21 days according to IEC 60512-11

## Dimensions

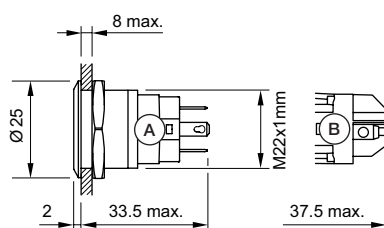


A = Solder terminal  
B = Screw terminal

## Mounting cut-outs

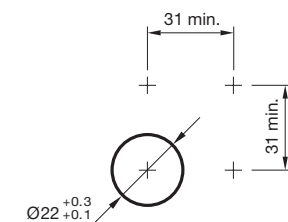

## Wiring diagrams

---

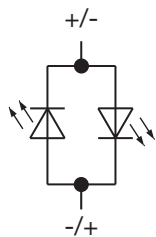

## Component layouts

---

