

B4 Series | Double-pole intermediate switch 2 momentary positions 16A quick connection 6.3 black body



sample image

PRODUCT CODE: B41J41100000

Wiring diagrams



Terminal type



Body colour



Actuator colour



Marking



Rating



16 A / 250 VAC
10 A / 250 VAC - 5E4
T120/55 °C

16 A / 125 VAC
10 A / 250 VAC
1/3 HP - 125 VAC
1/2 HP - 250VAC
T105 °C


Approvals



Dimensions (mm)

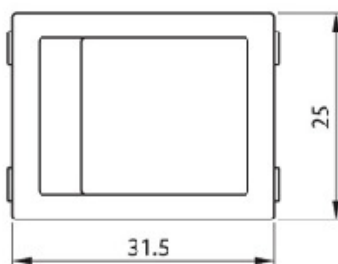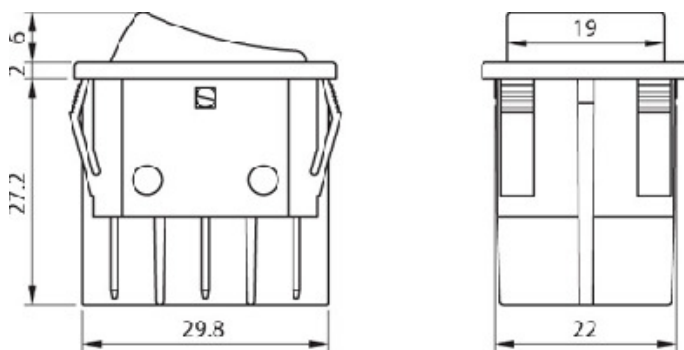

Cut out (mm)

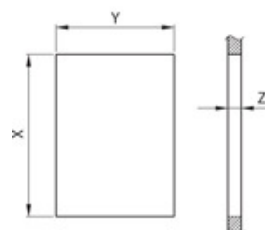

Z	Y	X
0.75 ... 1.25	22.0 ^{+0.2} ₀	30.0 ⁰ _{-0.1}
1.25 ... 2.0	22.0 ^{+0.2} ₀	30.2 ⁰ _{-0.1}
2.0 ... 3.0	22.0 ^{+0.2} ₀	30.6 ⁰ _{-0.2}
3.0 ... 4.0	22.0 ^{+0.2} ₀	30.8 ⁰ _{-0.2}