




Datasheet

RS PRO DC FAN 80x38mm

Stock Number: 703-3448

EN

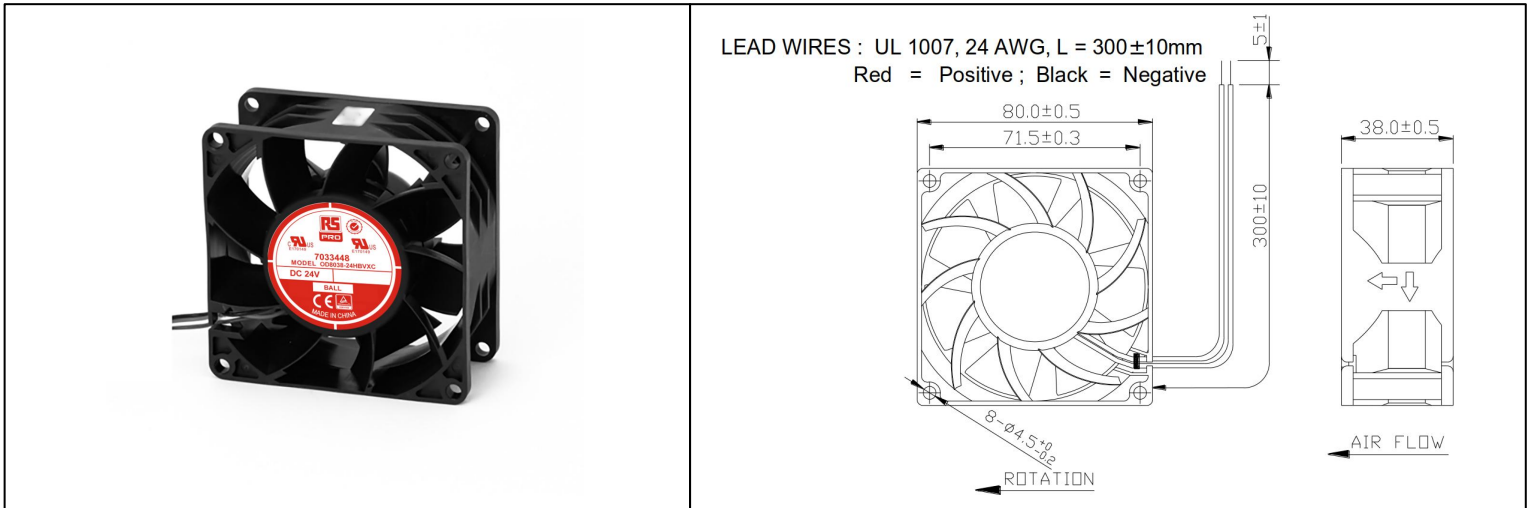

Frame	PBT UL94 V-0 Plastic	<u>Operating Temperature</u> -10°C ~ +70°C	
Impeller	PBT UL94 V-0 Plastic	<u>Storage Temperature</u> -40°C ~ +70°C	
Connection	2x Wire Leads, 24 AWG	<u>Life Expectancy</u> 70,000 hours (L10 at 40°C)	
Motor	Brushless DC, Auto Cutoff, Auto Restart, Polarity Protected	Weight: 0.195Kgs (0.43 lbs)	
Bearing System	Ball Bearing		
Dielectric Strength	500VAC/min < 1mA		
Insulation Resistance	10M ohm between leadwire and frame (500VDC)		

Model Number	703-3448
Rated Voltage	24 VDC
Rated Power	15.6 W
Rated Current	0.65 A
Rated Speed (RPM)	6200
Airflow (CFM)	97
Noise Level (dB)	57
Max. Static Pressure	0.80" H ₂ O