


Part No.	"G" mm	"F" Panel thickness mm	"A" mm	"B" mm	"C" mm	"D" mm	"E" mm	Style
SRT-3035	3.1 - 3.2	1.0 - 2.0	10.0	8.0	3.5	3.0	6.6	1
SRT-3045		2.0 - 3.0			4.5			
SRT-3055		3.0 - 4.0			5.5			
SRT-3065		4.0 - 5.0			6.5		9.0	
SRT-3075		5.0 - 6.0			7.5			
SRT-3080		5.5 - 6.5			8.0			
SRT-3535	3.6 - 3.7	3.8 - 5.2	12.0	8.0	3.5	3.5	6.6	2
SRT-3545		2.0 - 3.0			4.5			
SRT-3555		3.0 - 3.7			5.5		9.0	
SRT-3570		3.8 - 5.2			7.0			
SRT-3580		3.8 - 5.2			8.0			
SRT-4050	4.1 - 4.2	2.5 - 3.5	12.0	8.0	5.0	4.0	7.6	2
SRT-4060		3.5 - 4.5			6.0			
SRT-4070		4.5 - 5.5			7.0		11.2	
SRT-4080		5.5 - 6.5			8.0			
SRT-4090		6.5 - 7.5			9.0			
SRT-4100		7.5 - 8.5			10.0			





SRT

SNAP RIVET, T-TYPE

STYLE 1

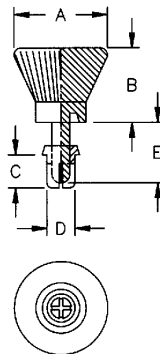

STYLE 2

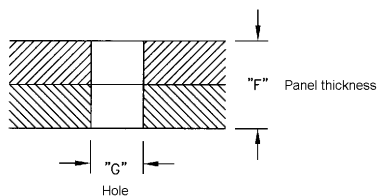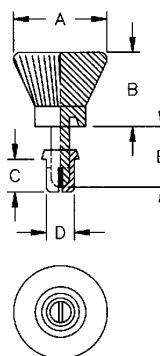

Material: Nylon 6 - black, UL 94 V-2, RMS-28
 Std. Pk.: 1.000 pcs.

Note:

SRT	3035	W or B
Part	Type	Colour