



PROTECTA® HARNESSES

THE NEW PROTECTA® PRO™ HARNESS RANGE

THE INDUSTRY WORK HORSE JUST GOT BETTER



TRUSTED FALL PROTECTION

FOR MANY YEARS THE PRO™ HARNESS RANGE HAS BROUGHT WORKERS HOME SAFELY, WHATEVER THEIR JOB.

The new improved Protecta® Pro™ harness design offers the same stringent safety standards but with improved comfort, adjustability, webbing management and functionality. The extensive model range remains as one of the widest in the industry. Whatever your job demands, there is a new Protecta® Pro™ harness for you.

BUCKLE OPTIONS

- Pass Through for simple, safe connection
- Quick Connect for fast and easily adjustable connection

CHEST STRAP

- Optimum position for connection to lanyards & systems
- Keeps connectors out of the users face

SPRING LOADED TORSO ADJUSTERS

- Spring loaded grip bar ensures no webbing slippage
- Easier to adjust with pull down adjustment

WEBBING MANAGEMENT

- Spare torso webbing stored through hip strap
- All stitch blocks are away from the body for greater comfort

REMOVABLE PADDING OPTIONS

- Can be fitted or removed by the user to any harness in the range
- Leg Padding: 9502120NG (Pack of 2 pads)
- Shoulder Padding equipped with Integrated Lanyard Keepers: AK096NG





LARGE REAR D RING

- Easier to connect, increased safety
- Can be used for Rescue

FALL INDICATORS

PROTECTED LABELS

- Protective Velcro™ sealed pouch
- Ensures easy identification & inspection

CONTRASTING LEG & CHEST STRAP

- Reduces donning time

SUB PELVIC STRAP

HARNES

Adjustable Shoulder & Thigh straps (Not AB100NG)
Adjustable Chest Strap
Impact Indicator (Not AB113PNG)

WEBBING

Polyester Width 45mm
Stitching: High-Strength Polyester Thread
Breaking Strength > 2600 daN

FITTING

High Strength Zinc-Plated Steel
Attachment D-Rings in Zinc-plated Steel
Energy Absorbing Dorsal Plate
Quick Adjustment Pass Thru Buckles (AB100NG, AB101NG, AB102NG, AB103NG, AB104NG, AB105NG, AB112NG, AB113NG, AB115NG, AB116NG)
Quick Connect Buckles (AB117NG, AB202NG, AB213NG, AB214NG, AB230NG, AB260NG)

SYSTEM BREAKING STRENGTH: >1500 DAN



AB100NG

←••••→				
S			0.82	AB10032NG
M/L			0.86	AB10033NG
XL			0.92	AB10034NG



AB101/19NG

←••••→						
M/L			2m	50 mm	2.20	AB101/19 NG
M/L			1.75 m	50 mm	2.20	AB101/19 UNG



AB101NG

←••••→				
S			1.28	AB10112NG
M/L			1.30	AB10113NG
XL			1.31	AB10114NG

AB10032/33/34NG			■			
AB101/19NG/19UNG			■			
AB10112/13/14NG			■			
AB10112HV/13HV/14HVNG			■			
AB10212/13/14NG		■	■			
AB10312/13/14NG			■			



AB101HVNG

←→				CE EN471
S			1.50	AB10112HVNG
M/L			1.56	AB10113HVNG
XL			1.60	AB10114HVNG



AB102NG

←→				
S			1.28	AB10212NG
M/L			1.30	AB10213NG
XL			1.31	AB10214NG



AB103NG

←→				
S			1.10	AB10312NG
M/L			1.15	AB10313NG
XL			1.20	AB10314NG

		■	■					■
	■	■	■					■
	■	■	■					■
	■	■	■					■
	■	■	■					■
■	■	■	■					■



AB112NG

←→	🔒	🌀	📏	
S	PT	PT	1.31	AB11212NG
M/L	PT	PT	1.36	AB11213NG
XL	PT	PT	1.41	AB11214NG



AB113NG

←→	🔒	🌀	📏	
S	PT	PT	1.13	AB11312NG
M/L	PT	PT	1.18	AB11313NG
XL	PT	PT	1.21	AB11314NG



AB113PNG

←→	🔒	🌀	📏	
S	PT	PT	1.38	AB11312PNG
M/L	PT	PT	1.43	AB11313PNG
XL	PT	PT	1.46	AB11314PNG

	⊙ CE EN361	2 CE EN361	🌀 CE EN361	⊙ CE EN358	Ⓜ CE EN1497	Ⓢ CE EN613
AB11212/13/14NG	■	■	■			
AB11312/13/14NG	■		■			
AB11312/13/14PNG	■		■			
AB11312HVNG/13HV/14HVNG	■		■			
AB11312/13/14GNG	■		■			
AB20212NG/13/14NG		■	■			



AB113HVNG

←→				CE EN471
S	PT	PT	1.62	AB11312HVNG
M/L	PT	PT	1.66	AB11313HVNG
XL	PT	PT	1.70	AB11314HVNG



AB113GNG

←→				
S	PT	PT	1.10	AB11312GNG
M/L	PT	PT	1.15	AB11313GNG
XL	PT	PT	1.20	AB11314GNG



AB202NG

←→				
S	QC	QC	1.42	AB20212NG
M/L	QC	QC	1.44	AB20213NG
XL	QC	QC	1.46	AB20214NG

	■	■	■					■
	■	■	■					■
	■	■	■				■	
	■	■	■					■
	■	■	■					■
	■	■	■					■

PROTECTA® HARNESSES



AB213NG

←····→				
S			1.34	AB21312NG
M/L			1.36	AB21313NG
XL			1.38	AB21314NG



AB230NG

←····→				
S			1.53	AB23012NG
M/L			1.69	AB23013NG
XL			1.73	AB23014NG



AB117NG

←····→				
S			1.20	AB11712NG
M/L			1.25	AB11713NG
XL			1.30	AB11714NG

AB21312/13/14NG	■		■			
AB23012NG/13/14NG			■			
AB11712NG/13/14NG	■		■		■	
AB11312R/13R/14RNG	■		■		■	
AB104125/135/145NG			■	■		
AB105125NG/35/45NG		■	■	■		



AB113RNG

←→				
S			1.20	AB11312RNG
M/L			1.25	AB11313RNG
XL			1.28	AB11314RNG



AB1041NG

←→					
S				1.83	AB104125NG
M/L				2.03	AB104135NG
XL				2.06	AB104145NG



AB1051NG

←→					
S				2.07	AB105125NG
M/L				2.14	AB105135NG
XL				2.21	AB105145NG

	■	■	■					■
■	■	■	■			■	■	■
	■	■	■					■
	■	■	■					■
	■	■	■	■	■			■
	■	■	■	■	■			■



AB1141NG

←.....→					
S	PT	PT	PT	2.02	AB114125NG
M/L	PT	PT	PT	2.06	AB114135NG
XL	PT	PT	PT	2.15	AB114145NG



AB2143NG

←.....→					
S	QC	QC	QC	2.30	AB214325NG
M/L	QC	QC	QC	2.40	AB214335NG
XL	QC	QC	QC	2.50	AB214345NG

	CE EN361	CE EN361	CE EN361	CE EN358	CE EN1497	CE EN613
AB114125NG/35/45NG	■		■	■		
AB214325/35/45NG	■		■	■		
AB260126/36/46NG			■	■		
AB35132/33/34	■		■	■		■



AB2601NG

←.....→					
S	CC	CC	CC	2.60	AB260126NG
M/L	CC	CC	CC	2.65	AB260136NG
XL	CC	CC	CC	2.70	AB260146NG



AB351

←.....→					
S	PT	PT	PT	1.84	AB35132
M/L	PT	PT	PT	1.86	AB35133
XL	PT	PT	PT	1.89	AB35134

	■	■	■	■	■			■
	■	■	■	■	■			■
■	■	■	■	■	■	■	■	■
	■	■		■	■	■		■



CONSTRUCTION KIT

- 1 x AB11313NG Harness
- 1 x AC410 10m Rope
- 1 x AC400 Viper™ mobile roped fall arrester
- 1 x AK053 Back Pack

CE EN361 CE EN353-2 CE EN362
AA095NG

kg

3.10



BUILDING KIT

- 1 x AB10213NG Harness
- 1 x AC210 10m Rope with AJ501 karabiner
- 1 x AC202/03 Cobra™ slider with 200mm line + AJ565 karabiner
- 1 x AK053 Back Pack

CE EN361 CE EN353-2 CE EN362

AA110NG

kg
4.00



ROOFING KIT

- 1 x AB21313NG Harness
- 1 x AC4015 15m Rope with AJ501 karabiner
- 1 x AC4001 Viper™ LT Rope Grab with Extension
- 1 x AK053 Back Pack
- 1 x AM450/80 Sling - Nylon Webbing: four safety seams

CE EN361 CE EN353-2 CE EN358

AA130NG

kg
6.00



BUILDING KIT

- 1 x AB11313NG Harness
- 1 x AC2000 FIRST™ slider on twisted 10m rope
- 2 x AJ501 Screw gate karabiner (x2)
- 1 x AK053 Back Pack

CE EN361 CE EN353-2 CE EN362

AA097NG

kg
3.10



CONSTRUCTION KIT

- 1 x AB11313NG Harness
- 1 x AC410 10m Rope with AJ501 karabiner
- 1 x AC400 Viper™ mobile roped fall arrester
- 1 x AM450/80 0.80m stitched loop, blue
- 1 x AK053 Back Pack

CE EN353-2 CE EN361 CE EN362 CE EN795 CLASS B

AA195NG

kg
3.15



ROOFING KIT

- 1 x AB11313NG Harness
- 1 x AC415 15m Rope with AJ501 karabiner
- 1 x AC401 Viper™ slider with line and AJ565 karabiner
- 1 x AK053 Back Pack

CE EN353-2 CE EN361 CE EN362

AA400NG

kg

3.70



INDUSTRIAL MAINTENANCE KIT

- 1 x AB10033NG Harness
- 1 x AD111 Rebel™ Webbing Fall Arrester, 3m
- 1 x AM450/80 0.80 m stitched loop, blue
- 1 x AK053 Back Pack

CE EN360 CE EN361 CE EN362 CE EN795 CLASS B

AA420NG

kg

2.90



METAL CONSTRUCTION KIT

- 1 x AB10033NG Harness
- 1 x AE522 Tear-web energy absorber, 2m in length, 2 AJ501 karabiners
- 1 x AM450/80 0.80 m stitched loop, blue
- 1 x AK053 Back Pack

CE EN361 CE EN355 CE EN362 CE EN795 CLASS B

AA410NG

kg

4.00





SHOULDER PADDING

	←.....→	kg
AK096NG	U	0.17



LEG PADDING

Pack of 2

	←.....→	kg
9502120NG	U	0.12



BACK D RING EXTENSION STRAP

Screw gate triangle to attach to harness

	←.....→	kg
AB011	40cm	0.19



BACK PACK

Red and grey Protecta® back pack

	←.....→	kg
AK053	15x30x50cm	0.44



BELT

Large fixed side D-Rings with tool loops

	←.....→	kg
AB051326	S	0.82
AB051336	M/L	0.83
AB051346	XL	0.84

EUROPE, MIDDLE EAST & AFRICA

France

Le Broc Center
Z.I. 1re Avenue – BP15
06511 Carros Le Broc Cedex
FRANCE

t: +33 (0)4 97 10 00 10
f: +33 (0)4 93 08 79 70

United Kingdom

5a Merse Road
North Moons Moat
Redditch, Worcestershire
B98 9HL UK

t: +44 (0) 1527 548 000
f: +44 (0) 1527 591 000

Dubai


ME Branch Office
PO Box 17789
JAFZA, Dubai – U.A.E

Germany

t: +49 (0)2 76 18 33 82 29

CHOOSING THE CORRECT SIZE OF HARNESS

Selecting the correct size of harness is not only essential for your safety and comfort but will also allow you to work more efficiently. Use the table here to choose the harness size that is best suited to you.

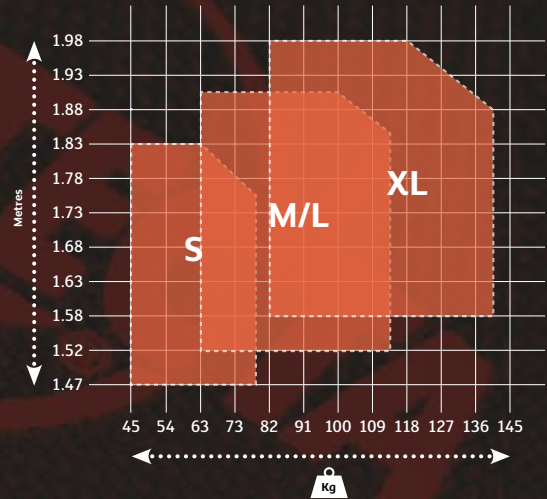

ICON KEY



Chest



Leg



Waist



Adjustable Shoulders



Adjustable Chest



Adjustable Leg



Adjustable Waist



Front Loops



Dorsal D-Ring



Dorsal Shock Absorber



Sternal D-Ring



Work Positioning



Pectoral D-Ring



Rescue Attachment Point



Suspension Attachment Point



Fall Indicator



Comfort Pads



Pass Through Buckle



Quick Connect Buckle

00 800 999 55500

information@capitalsafety.com
www.capitalsafety.com

