


2005-TS-147

Tool trolley with tool assortment

147 pieces

Code	ETIM
2980282	EC000149
EAN	UNSPSC
4010886948422	27-11-32-01
Country of origin	eCl@ss
Germany	21-07-11-00
Customs tariff number	
82060000	

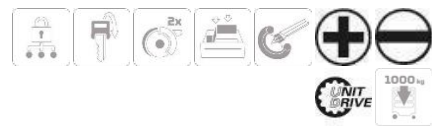

Article description

- For industry, the trades, automotive
- Tools in metric dimensions
- GEDORE Check-Tool-System: 2-colour foam insert to check that the set is complete
- In tool trolley No. 2005 0511
- Non-slip, with recessed grip

Article parts list

1/4" Reversible ratchet No. 2093 U-20 ,1/4" Wobble extension No. 2090 KR-4 ,1/4" T-handle No. 2087 ,1/4" Socket UD-profile No. D 20 4 5 5.5 6 7 8 9 10 11 12 13 ,1/4" Socket insert No. TX 20 E4 E5 E6 E7 E8 E10 ,1/4" Screwdriver bit slotted No. 680 4 5.5 6.5 8 ,1/4" Screwdriver bit in-hex No. 685 2.5 3 4 5 6 ,1/4" Screwdriver bit XZN No. 685 X 5 6 8 ,1/4" Screwdriver bit PH No. 690 1 2 3 ,1/4" Screwdriver bit PZ No. 690 PZD 1 2 3 ,1/4" Screwdriver bit TX No. 687 TX T6 T7 T8 T9 T10 T15 T20 T25 T27 T30 T40 ,1/4" Multi handle No. 676 ,1/4" Bit holder No. 699 ,1/2" Reversible ratchet No. 1993 U-20 ,1/2" Extension No. 1990-2.1/2 ,1/2" Wobble extension No. 1990 KR-5 -10 ,1/2" Socket No. D 19 10 11 12 13 14 15 16 17 18 19 21 22 24 27 30 32 ,1/2" Screwdriver socket in-hex No. IN 19 5 6 7 8 9 10 12 14 ,Insert holder 1/4" hexagon - 1/4" square No. 673 6.3 ,Bit-Adapter 1/4" hexagon - 1/4" square No. 620 ,Combination spanner UD-profile No. 7 8 9 10 11 12 13 14 15 16 17 18 19 20 21 22 24 ,Allen Key set No. PH 42-88 (2-10 mm) ,3C-Screwdriver slotted No. 2154SK 3.5 5.5 6.5 8 ,3C-Screwdriver PH No. 2160SK PH 1 2 ,Universal pliers No. 142 10 TL ,Power combination pliers No. 8250-180 JC ,Multiple pliers No. 8133-200 JC ,Power side cutters No. 8316-180 JC ,Engineer's hammer No. 4 E-500 ,Centre punch No. 100-12 ,Pin punch No. 119-1,5 -3 -4 ,Flat chisel No. 97-250 ,Cross-cut chisel No. 98-125 ,Drift punch No. 99 12-5 ,Twist drill set No. 8550-024

Article information

Contents (Qty of pieces)	147	Material	sheet steel
Net weight [kg]	104,3 kg	Storage	Tool trolley
Total length [mm]	865 mm	Number of drawers	7
Total width [mm]	605 mm	Drawer type	7 drawers: 5x Typ 1, H = 67 mm 1x Typ 2, H = 137 mm 1x Typ 3, H = 207 mm
Total height [mm]	1.020 mm	Single pull-out stop	no