

FEATURES

- Steel short clevis
- Spring clip
- M8 x 1.25 rod connection thread
- Ball diameter of 8mm
- Overall length of 58mm
- Overall width of 32mm
- Zinc finish for corrosion-resistant finish

RS PRO Steel M8 x 1.25 Clevis, 58mm x 32mm

RS Stock No.: 312-0264



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These high-quality clevis fasteners have long forks and a U-shaped construction that allows them to bear considerable weight. They ensure a more flexible connection when compared with many other fasteners, making them the reliable option for agriculture, sailing and the automotive and aviation industries.

General Specifications

Accessory Type	Clevis
Rod Connection Thread	M8 x 1.25
Material	Steel
Finish	Zinc
Applications	Food, medical, petrochemical aviation and agriculture industries

Mechanical Specifications

Overall Length	58mm
Overall Width	32mm
Ball Diameter	8mm


Approvals

Compliance/Certifications	BS970pt1 1983 220 MOT, BS970 pt. 5 1972 270 A72, DIN 71752
----------------------------------	--



Dimensions (mm)											
Thread A	B	C	D	E	Ø F	G	Ø H	J	K	L	Ø M
M8x1.2 5	58	32	16	8.15/8. 30	8	12.0	14	48	47	19	8

Clevis

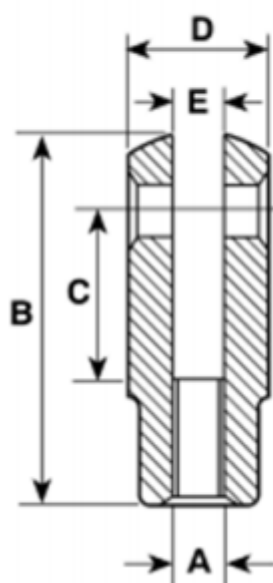

**Clevis pin
-spring clip**

