



Figure similar

SITOR cylindrical fuse link, 22x58 mm, 40 A, aR, Un AC: 690 V, Un DC: 500 V, DC according to UL, Striker indicator

Model	
product brand name	SETRON
product designation	SITOR cylindrical fuse link
design of the product	DC acc. to UL
design of an identification indicator	Striker indicator
General technical data	
operating class of the fuse link	aR
type of voltage of the operating voltage	AC
supply voltage at DC	500 V
Dissipation	
power loss [W]	9 W
power loss [W] for rated value of the current at AC in hot operating state per pole	9 W
Main circuit	
operational current rated value	40 A
Product details	
product component striker	Yes
Mechanical Design	
mounting position	Any, preferably vertical
net weight	64 g
Approvals Certificates	
General Product Approval	other



[Confirmation](#)

Environment

[Environmental Confirmations](#)

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC2240-5>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NC2240-5>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC2240-5

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

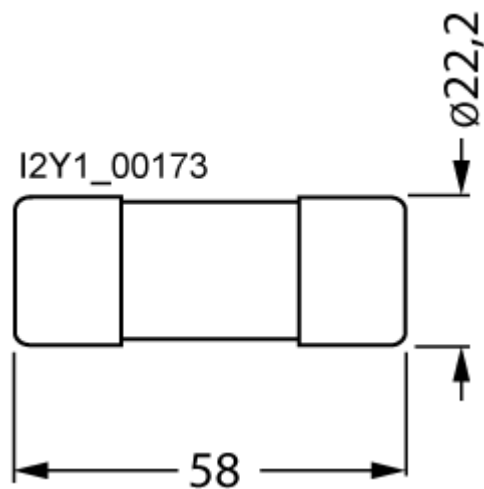

last modified:

4/11/2025 

