


KEMET Part Number: SN8D-400JB
(UALSN8D400JB00)

KEMET, SN-JB, AC Line Filters, Normal Mode, 80 uH

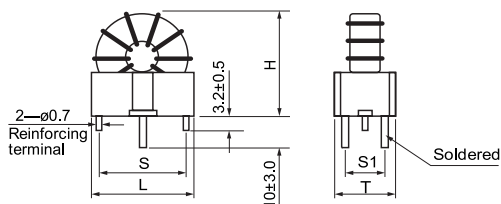

Dimensions

L	18.5mm MAX
T	15.5mm MAX
H	18mm MAX
LL	10mm +/-3mm
S	14mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	910
Weight:	8.4 g

General Information

Series:	SN-JB
Style:	Through-Hole
RoHS:	Yes
Miscellaneous:	24 (K) Temperature Rise Max.

Specifications

Inductance:	80 uH (0.1 MHz)
Current:	2 A
Temperature Range:	-25/+105°C
DC Resistance:	85 mOhms