





Notes: (Unless Otherwise Specified)

1. Waterproof Rate: IP68.
2. Cable Diameter: 5.0 to 6.0 mm
3. Recommend Cover Torque: 6.0 to 7.0 Kgf-cm.
4. Recommend Gland Nut Torque: 9.0 to 10.0 Kgf-cm.
5. RoHS Compliant.

REV	ECN#	DESCRIPTION OF REVISION	DRAW BY DATE	CHECK BY DATE	APPROVE BY DATE
A0	ECN-140113	Mass Production	Joyce 01/29/14	Lucas 01/29/14	Ray 01/29/14

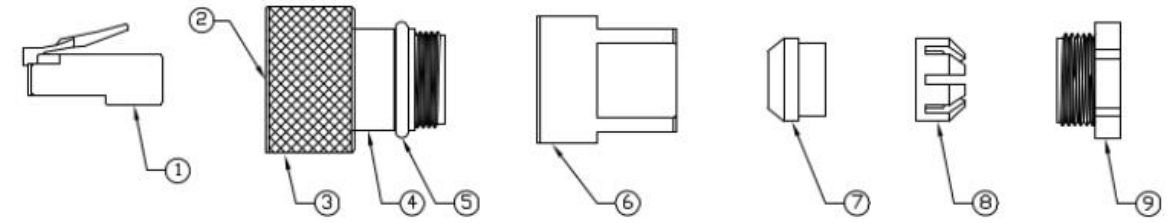

Item	Part Name	Material / Finish	Qty
9	Metal Gland Nut	Copper Alloy Finish: Ni Plated	1
8	Cage	Thermoplastic Color: White	1
7	Gland	Silicone Color: Green	1
6	Metal Cover	Copper Alloy Finish: Ni Plated	1
5	O-Ring	Silicone Color: Red	1
4	Housing	Thermoplastic Color: Black	1
3	Metal Screw Nut	Copper Alloy Finish: Ni Plated	1
2	Rubber Pad	Silicone Color: Black	1
1	RJ45 Plug	Housing: Thermoplastic, Color: Clean Contacts: Copper Alloy Finish: Au Plated Shell: SPCC, Finish: Ni Plated	1

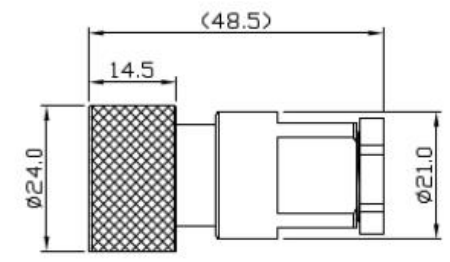

Mating Parts:
111-6739
111-6740

TITLE							RS Stock No		
RJ45 Full Metal C3 Shilded Field Installable Cable End Screw							111-6743		
THIRD ANGLE PROJECTION	SIZE	SCALE	DRAW / DATE	CHECK / DATE	APPROVE / DATE	TOLERANCES	UNIT	SHEET	
	B	1:1	Joyce 01/29/14	Lucas 01/29/14	Ray 01/29/14	XX ± 0.5 XXX ± 0.2	X,XXX ± 0.05 ANGLES ± 1°	mm 1/1	